


Mouse Type Transformer

Dimmable



Dimension in mm

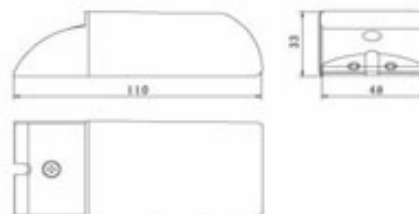

■ Features

- IP 20 dimmable independent transformer,
- Class II protection against electric shock following direct and indirect contact,
- Dimmable for both leading-edge and phase cutting trailing edge dimmer,
- Very small compact size,
- Easy assembly and installation,
- Protected against short-circuits,
- Protected against mains voltage spikes,
- Protected against overloads and overheating (safety failure),
- The latest VDE standard approval.



Model No.	Rated supply	Rated current	Load	Output voltage	Ta	Tc	Wiring	Size(mm)
SET70M	AC230-240V	0.30A	20-70W	11.6V rms	50°C	75°C	Terminal Blocks	110X48X33
SET105M	AC230-240V	0.46A	35-105W	11.6V rms	45°C	75°C	Terminal Blocks	110X48X33

