

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

5034804000

Status:


Active

Overview:

Easy-On FFC FPC Connectors

Description:

Easy-On FFC/FPC Connector, 0.50mm Pitch, FBH1 Series, Right-Angle, Dual Contact, 1.00mm Height, 40 Circuits, Gold over Nickel Plating

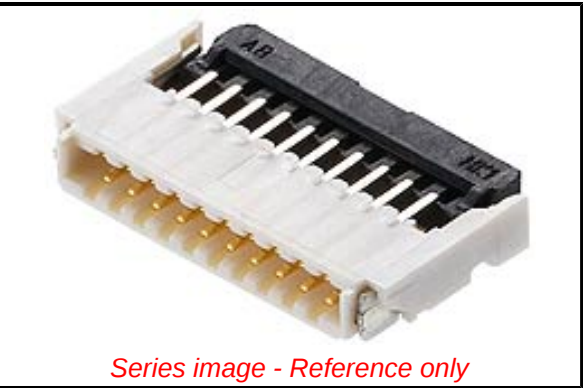

Documents:	
3D Model	Datasheet (PDF)
Drawing (PDF)	Product Guide (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-503480-001-001 (PDF)	Reference Guide (PDF)

General	
Product Family	FFC/FPC Connectors
Series	503480
Comments	Black Actuator
Overview	Easy-On FFC FPC Connectors
Product Name	Easy-On
Series Name	FBH1
UPC	887191355276
Physical	
Actuator Type	Back Flip
Circuits (Loaded)	40
Color - Resin	Natural (White)
Contact Position	Dual
Durability (mating cycles max)	10
Mated Height	1.00mm
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Plating Termination	Gold
Material - Resin	Liquid Crystal Polymer
Net Weight	135.290/mg
Number of Rows	1
Orientation	Right Angle
PCB Locator	No
PCB Mounting	Surface Mount
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.50mm
Polarized to PCB	Yes
Stackable	No
Temperature Range - Operating	-40° to +85°C
Wire/Cable Type	FFC/FPC
Electrical	
Current - Maximum per Contact	0.5A
Voltage - Maximum	50V
Material Info	
Reference - Drawing Numbers	
Product Specification	PS-503480-001-001
Sales Drawing	SD-503480-001-001, SD-503480-002-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2020)9139-DC (19 Jan 2021)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
503480 Series

Mates With
Premo-Flex FFC Cable 15020

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION