



EPIC® Rectangular Connectors

MC Series Plugs & Receptacles

 

 
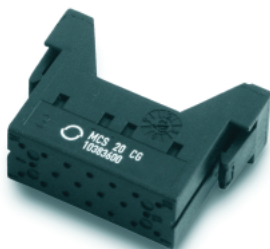


DUMMY MODULES: 0 CONTACTS

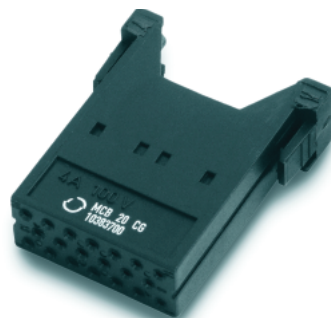



Plug

Receptacle

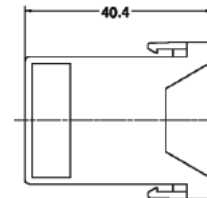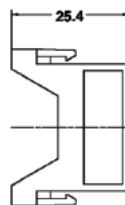



Plug	Receptacle
10399400	10399500

CAGE CLAMP MODULES: 4 CONTACTS

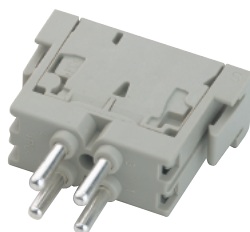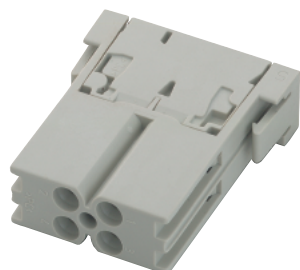


Plug

Plug

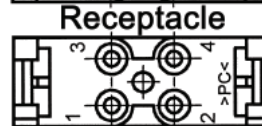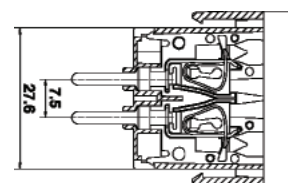

Receptacle

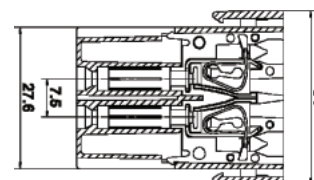


Rated Voltage:
400V

Rated Current:
14A


Plug	Receptacle
10399600	10399700

Wire Gauge

 Single Wire: 4.0 mm²
Fine Wire: 2.5 mm²



PROFIBUS DP MODULES: 2 CONTACTS & SHIELD

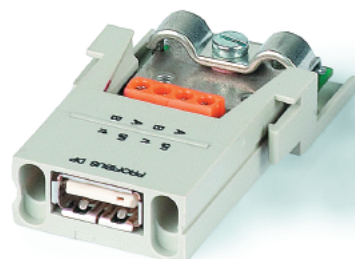


Rated Voltage:
30V

Rated Current:
1A

Plug

Receptacle

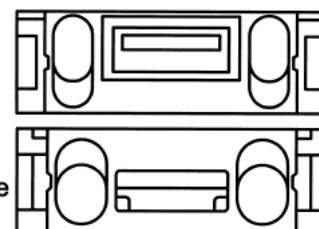

Mount in High Profile Housings only.

Plug	Receptacle
10390400	10390500