

# EPIC® Rectangular Connectors





MC Series Plugs & Receptacles

## 10 CONTACT MODULES: MACHINE CRIMP CONTACTS



Contacts Sold Separately

Plug	Receptacle
10382400	10382500

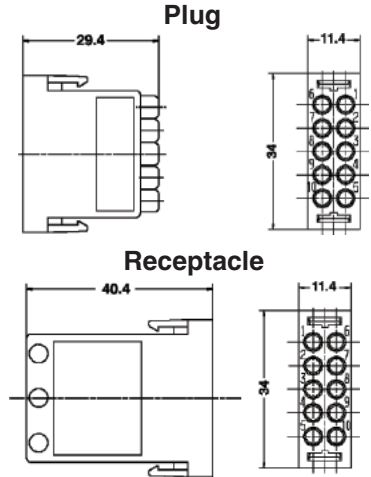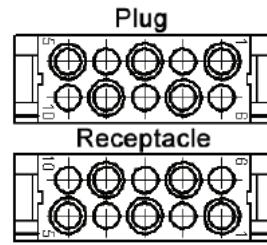


**Rated Voltage:**  
250V

**Rated Current:**  
10A

## MACHINE CONTACTS: DIAMETER 1.6 MM

 Cross section characteristic



Bags of 100

mm <sup>2</sup>	AWG	Silver		Gold		Stripping Length (mm)	# of Marking Tracks
		Pin	Socket	Pin	Socket		
0.14 - 0.37	26 - 22	13162000	13163000	13162500	13163500	8	1
0.5	20	13162100	13163100	13162600	13163600	8	2
0.75 - 1.0	18	13162200	13163200	13162700	13163700	8	3
1.5	16	13162300	13163300	13162800	13163800	8	4
2.5	14	13162400	13163400	13162900	13163900	5.8	5

Part number= 1 contact

## CRIMP TOOLS



 
**Crimp Tool**  
11147000



**Crimp Dies**  
11147100



**Locator**  
11147200



**Removal Tool:**  
11161000

## FIBER OPTIC CONTACTS & TOOLS



Pin	Socket
11214100	11219100

**Fiber Optic Assembly Tool Set**  
11184700

