

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [2152703603](#)  
**Status:** **Active**  
**Overview:** Temperature Sensor Cable Assemblies  
**Description:** Epoxy Coated NTC Thermistor Cables, 25.00mm Length, 3600 Beta Value, 10k# Resistance at 25°C with 1% Tolerance, Green

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Cable Assemblies
Series	<a href="#">215270</a>
Application	Temperature Sensing
Assembly Configuration	Single Ended Connector
Beta Value (K)	3600
Connector to Connector	NTC Thermistor-to-Pigtail
Overview	<a href="#">Temperature Sensor Cable Assemblies</a>
Product Name	NTC Temperature Sensor
Resistance Tolerance (%)	1
Resistance at 25°C (kohms)	10
UPC	195842044555


**Physical**

Cable Length	25.00mm
Circuits (Loaded)	1
Color - Resin	Green
Gender	N/A
Lock to Mating Part	Yes
Net Weight	0.110/g
Packaging Type	Bag
Single Ended	Yes
Wire Size AWG	28
Wire/Cable Type	N/A

**Material Info**

**Reference - Drawing Numbers**

Sales Drawing 2152703603-000

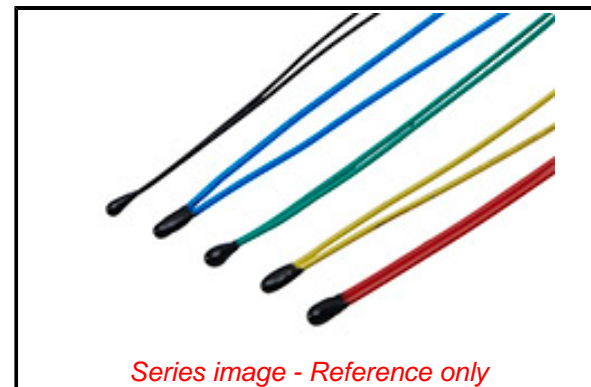

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant with Exemption 15(a)**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Contained

**Search Parts in this Series**

[215270 Series](#)