


AUDIOJoG PRO 8

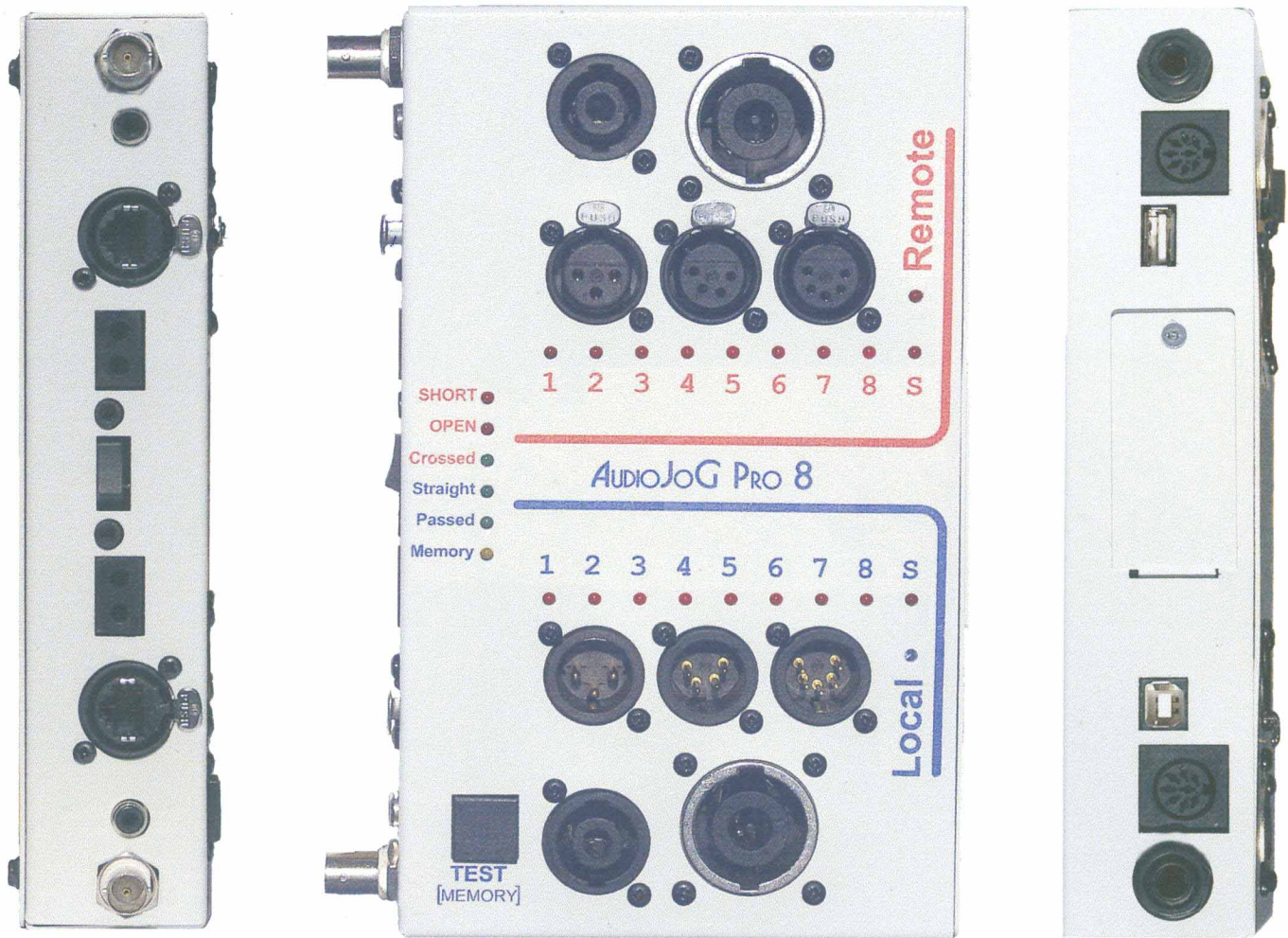

LEFT

- BNC 50 ohm
- RCA Phono
- RJ45
- Single or Twin 4.4mm Bantam, stereo or mono
- 3.5mm Jack, stereo or mono

CONNECTORS TOP

- 3, 4 & 5 Pole XLR Male (Local)
- 3, 4 & 5 Pole XLR Female (Remote)
- 4 & 8 Pole Speakon

RIGHT

- 6.35mm Jack, stereo or mono
- DIN 3, 5 (180°) & 8 Pole
- USB A (Local)
- USB B (Remote)

SPECIFICATION

- Continuity and Short Circuits, less than 255K {75K} ohms
- Open Circuits (end to end and between connected pins), greater than 255K {75K} ohms
- Less than 2 {5} second test time
- Sturdy METAL BOX construction
- L 203mm W 150mm D 50mm
- Uses 9v PP3 battery (not supplied)

AUDIOJoG PRO 8 by CableJoG Ltd. 18 Browmere Drive, Croft, Warrington. WA3 7HT.

Tel: 01925 764 471 Fax: 01925 764 903 web www.cablejog.com