

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [2178511126](#)
Status: **Active**
Overview: [Off-the-Shelf Pre-Crimped Leads](#)
Description: Pre-Crimped Lead Perma-Seal-to-Pigtail, Solderless, Tin (Sn) Plating, 600.00mm Length, Red

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Datasheet \(PDF\)](#)

General

Product Family	Cable Assemblies
Series	217851
Assembly Configuration	Pre-crimped Lead Only
Connector to Connector	Perma-Seal-to-Pigtail
Overview	Off-the-Shelf Pre-Crimped Leads
Product Name	Perma-Seal
Stud Size	10 (M5)
UPC	195842209916

Physical

Cable Length	600.00mm
Circuits (Loaded)	1
Color - Resin	Red
Gender	N/A
Lock to Mating Part	No
Material - Plating Mating	Tin
Material - Resin	PVC
Net Weight	14.340/g
Number of Rows	1
Packaging Type	Bag
Single Ended	Yes
Wire Insulation Diameter	5.97mm
Wire Size AWG	16
Wire/Cable Type	UL 1015


Electrical

Current - Maximum per Contact	20.0A
Voltage - Maximum	600V

Material Info

Reference - Drawing Numbers

Sales Drawing	2178511112-000
---------------	----------------

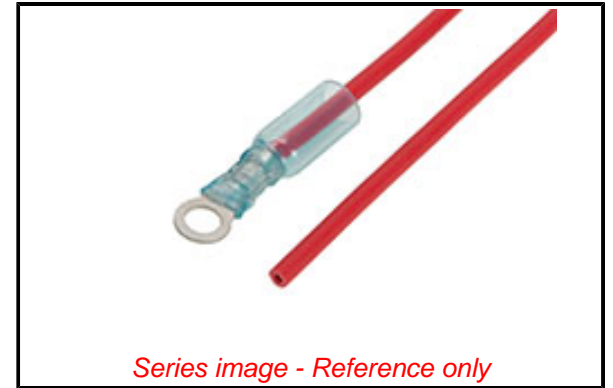

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2020)9139-DC (19
Jan 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[217851](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION