

## Han TC300 female contact 120mm<sup>2</sup>

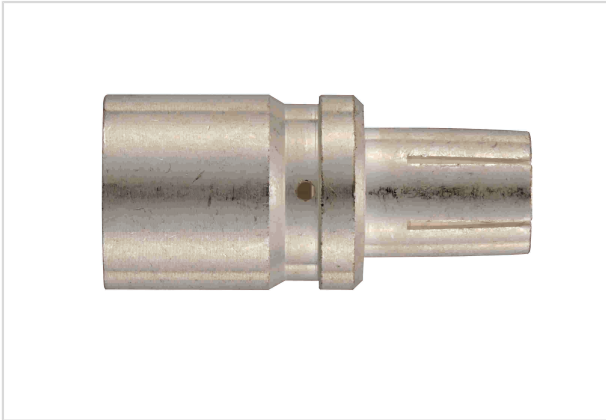


Image is for illustration purposes only. Please refer to product description.

Part number	09 11 000 6637
Specification	Han TC300 female contact 120mm <sup>2</sup>
HARTING eCatalogue	<a href="https://b2b.harting.com/09110006637">https://b2b.harting.com/09110006637</a>

### Identification

Category	Contacts
Type of contact	Crimp contact

### Version

Gender	Female
Manufacturing process	Turned contacts

### Technical characteristics

Conductor cross-section	120 mm <sup>2</sup>
Operating current	≤300 A
Contact resistance	≤0.3 mΩ
Stripping length	22.5 mm
Limiting temperature	-40 ... +125 °C

### Material properties

Material (contacts)	Copper alloy
Surface (contacts)	Silver plated

### Specifications and approvals

Specifications	EN 60664-1 IEC 61984
----------------	-------------------------

### Commercial data

Packaging size	1
----------------	---



Pushing Performance

## Commercial data

Net weight	45 g
Country of origin	Germany
European customs tariff number	85366990
eCl@ss	27440204 Contact for industrial connectors