

Han TC300 female contact 95mm²

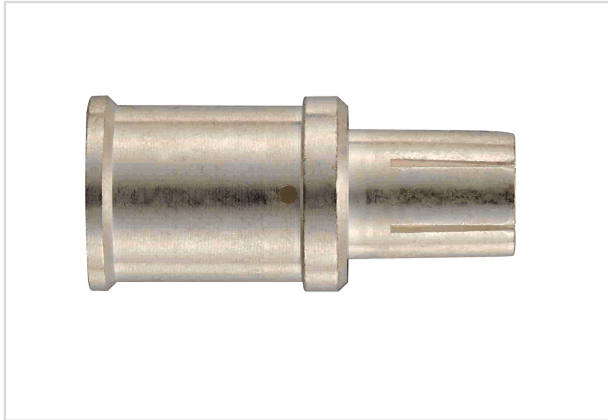


Image is for illustration purposes only. Please refer to product description.

Part number	09 11 000 6636
Specification	Han TC300 female contact 95mm ²
HARTING eCatalogue	https://b2b.harting.com/09110006636

Identification

Category	Contacts
Type of contact	Crimp contact

Version

Gender	Female
Manufacturing process	Turned contacts

Technical characteristics

Conductor cross-section	95 mm ²
Operating current	≤300 A
Contact resistance	≤0.3 mΩ
Stripping length	22.5 mm
Limiting temperature	-40 ... +125 °C

Material properties

Material (contacts)	Copper alloy
Surface (contacts)	Silver plated

Specifications and approvals

Specifications	EN 60664-1 IEC 61984
----------------	-------------------------

Commercial data

Packaging size	2
----------------	---



Pushing Performance

Commercial data

Net weight	1 g
Country of origin	Germany
European customs tariff number	85366990
eCl@ss	27440204 Contact for industrial connectors