

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [2167592036](#)
Status: **Active**
Overview: [EXTreme Guardian System](#)
Description: EXTreme Guardian-to-Pigtail Off-the-Shelf (OTS) Cable Assembly, 11.00mm Pitch, Single Row, 4.0m Length, 3 Circuits, Black

Documents:

[Drawing \(PDF\)](#)

[Datasheet \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable Assemblies
Series	216759
Application	Wire-to-Board, Wire-to-Wire
Assembly Configuration	Single Ended Connector
Connector to Connector	EXTreme Guardian-to-Pigtail
Overmolded	Yes
Overview	EXTreme Guardian System
Product Name	EXTreme Guardian
Type	High Reliability Assembly, Overmolded Assembly
UPC	195842228207

Physical

Cable Length	4.0m
Circuits (Loaded)	3
Color - Resin	Black
Gender	Female-Pigtail
Lock to Mating Part	Yes
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Resin	Polyester
Net Weight	3027.000/g
Number of Rows	1
Packaging Type	Bag
Pitch - Mating Interface	11.00mm
Single Ended	Yes
Termination Interface: Style	Crimp or Compression
Wire Size AWG	6
Wire/Cable Type	PVC


Electrical

Current - Maximum per Contact	50.0A
Voltage - Maximum	600V

Material Info

Reference - Drawing Numbers

Sales Drawing	2012344458-000
---------------	----------------

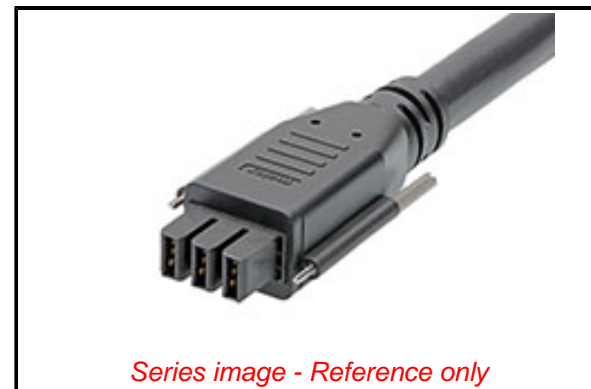

Series image - Reference only

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2020)9139-DC (19
Jan 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Compliant

Not Contained

Search Parts in this Series

[216759 Series](#)

Mates With

[46817](#) EXTreme Guardian 3 Circuit Power Plug Assembly