

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [2174651052](#)  
**Status:** **Active**  
**Overview:** [Ultra-Fit Power Connectors](#)  
**Description:** Ultra-Fit Tangless Female-to-Ultra-Fit Tangless Female Off-the-Shelf (OTS) Cable Assembly, 3.50mm Pitch, Single Row, 300.00mm Length, 5 Circuits, Black

**Documents:**

[Drawing \(PDF\)](#)

[Datasheet \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Cable Assemblies
Series	<a href="#">217465</a>
Application	Power, Wire-to-Board
Assembly Configuration	Dual Ended Connectors
Connector to Connector	Ultra-Fit-to-Ultra-Fit
Overmolded	No
Overview	<a href="#">Ultra-Fit Power Connectors</a>
Product Name	Ultra-Fit
Type	Discrete Wire Assembly
UPC	195842062092

**Physical**

Cable Length	300.00mm
Circuits (Loaded)	5
Color - Resin	Black
Gender	Female-Female
Lock to Mating Part	Yes
Material - Metal	High Conductivity Copper
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Nylon
Net Weight	27.056/g
Number of Rows	1
Packaging Type	Bag
Pitch - Mating Interface	3.50mm
Plating min - Mating	1.524µm
Plating min - Termination	1.524µm
Single Ended	No
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	2.03-2.39mm
Wire Size AWG	16
Wire/Cable Type	UL 1061


**Electrical**

Current - Maximum per Contact	14.0A
Voltage - Maximum	600V AC (RMS)/DC

**Material Info**

**Reference - Drawing Numbers**

Sales Drawing	2174651051-000
---------------	----------------

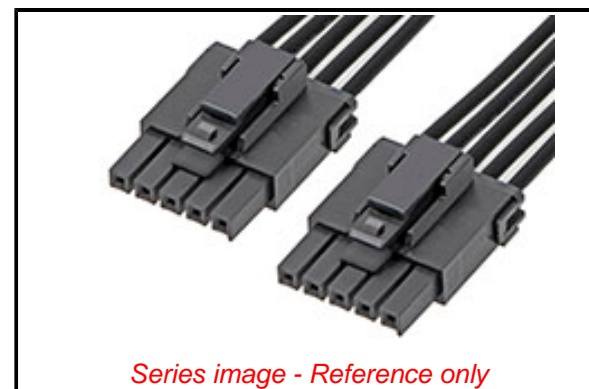

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2020)9139-DC (19  
Jan 2021)

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[217465 Series](#)