


HIGH-VOLTAGE CERAMIC DISC CAPACITORS



Specifications:

- Voltage: 1000V DC
- Tolerance: $\pm 10\%$
- Temperature characteristic (Y5P): $\pm 10\%$
- Dissipation factor ($\tan \delta$): 2.5%
- Operating temperature: -25°C to $+85^{\circ}\text{C}$
- Insulation resistance (IR) @ 25°C : 10.000M Ω
- Dielectric strength: 2X rated WVDC

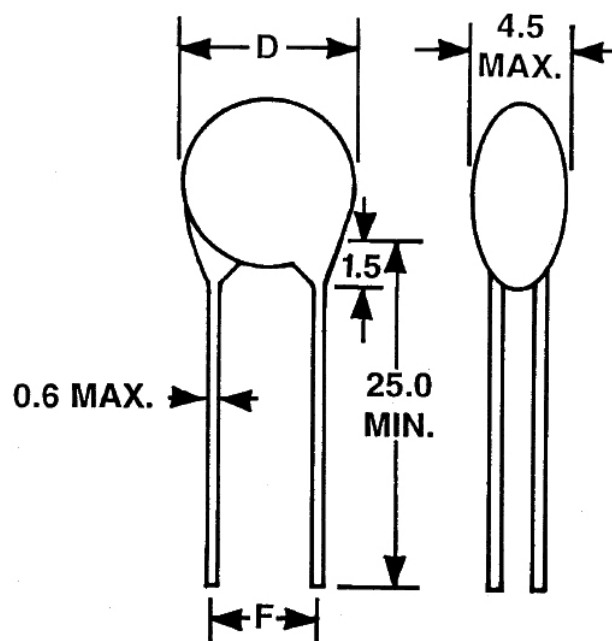

Capacitance (pF)	D x T (mm)	Mftrs. List No.	Order Code
100	6.5 x 6.35	MCC11B101K3AS6L-RH	1202813
220	6.5 x 6.35	MCC11B221K3AS6L-RH	1692259
330	6.5 x 6.35	MCC11B331K3AS6L-RH	1186137
820	6.5 x 6.35	MCC11B821K3AS6L-RH	1208279
1000	6.5 x 6.35	MCC11B102K3AS6L-RH	1692257
3300	11 x 6.35	MCC11B332K3AS6L-RH	1247096
4700	14 x 9.52	MCC11B472K3AS6L-RH	1186142
5600	15 x 9.52	MCC11B562K3AS6L-RH	1247097
6800	17 x 9.52	MCC11B682K3AS6L-RH	1247099
10000	19 x 9.52	MCC11B103K3AS6L-RH	1650710