

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2152793605

Status:


Active

Overview:

Temperature Sensor Cable Assemblies

Description:

Epoxy Coated NTC Thermistor Cables, 40.00mm Length, 4035 Beta Value, 10k# Resistance at 25°C with 1% Tolerance, Black

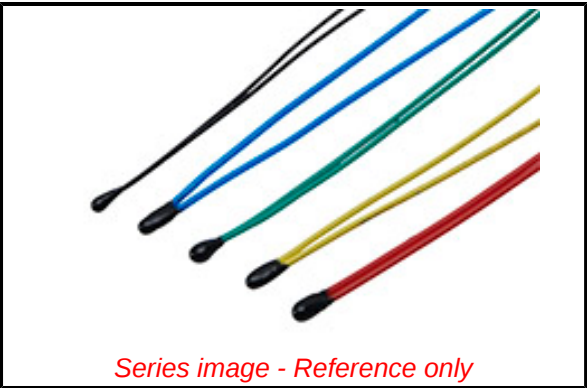

Documents:

[Drawing \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

[Datasheet \(PDF\)](#)

General	
Product Family	Cable Assemblies
Series	215279
Application	Temperature Sensing
Assembly Configuration	Single Ended Connector
Beta Value (K)	4035
Connector to Connector	NTC Thermistor-to-Pigtail
Overview	Temperature Sensor Cable Assemblies
Product Name	NTC Temperature Sensor
Resistance Tolerance (%)	1
Resistance at 25°C (kohms)	10
UPC	195842045231
Physical	
Cable Length	40.00mm
Circuits (Loaded)	1
Color - Resin	Black
Gender	N/A
Lock to Mating Part	Yes
Net Weight	0.150/g
Packaging Type	Bag
Single Ended	Yes
Wire Size AWG	28
Wire/Cable Type	N/A
Material Info	
Reference - Drawing Numbers	
Sales Drawing	2152793605-000

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 15(a)	
REACH SVHC	
Contained Per - D(2020)9139-DC (19 Jan 2021)	
Lead	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

215279 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION