

SPANNFIX – CLAMPING TOOLS WITH BALL JOINT

WHAT OUR CLAMPING TOOLS DISTINGUISHES


The SPANNFIX is a multifunctional vice with a flexible head and many possible applications.

By using the high-quality ball joint, the SPANNFIX head can be tilted and fixed in any direction and offers optimum hold in any position.

The ball mobility can be individually adjusted with the help of an adjusting screw on the lower seat of the ball.

The ball is fixed and released with a simple movement of the lever.

Long service life is guaranteed by the high-quality, powder-coated cast aluminium and surface-coated steel parts.

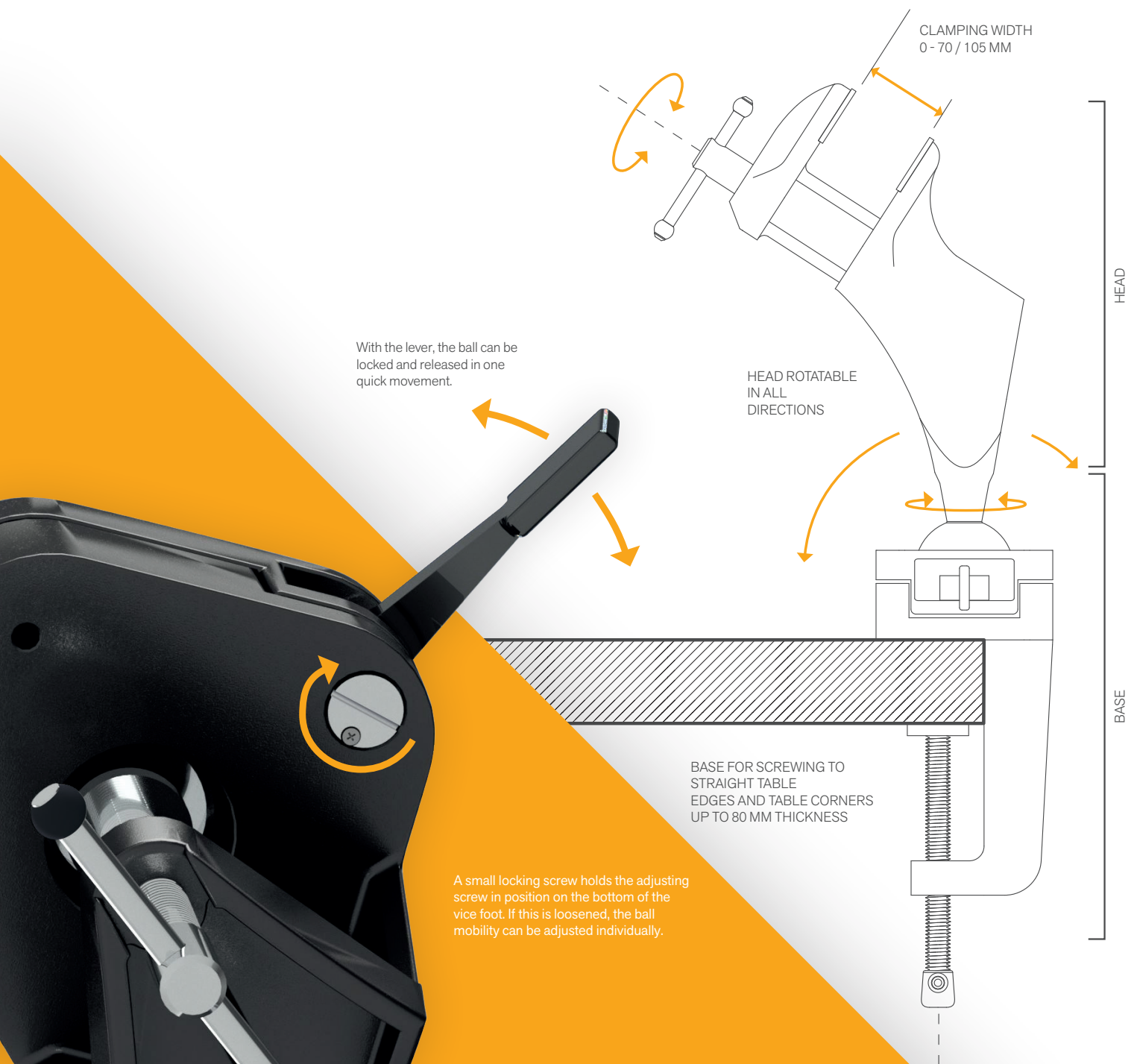

MODELS AND TYPES

The Spannfix is available in the models STANDARD, VARIO, MAXI and 4.0. The STANDARD and VARIO models are also manufactured in different colours. The Spannfix VARIO offers the possibility to combine bases with different heads for various applications.

Bases by BERNSTEIN are frequently used for mounting customers' own constructions.

The item numbers shown in the table are described in the following pages.



NEW

Model	STANDARD		VARIO			SPANNFIX MAXI	SPANNFIX 4.0
Jaw width/material	50 mm / plastic		50 mm / plastic			100 mm / steel	100 mm / steel
Ball diameter	Ø 40 mm		Ø 40 mm			Ø 60 mm	Ø 60 mm
Construction	solid		modular			solid	solid
Features	Components are firmly connected to each other		Head and base can be individually combined with one another (except Art.-No. 9-262)			Large design, components are firmly connected to each other	Large design, components are firmly connected to each other
Colour variations	dark grey	ESD black	dark grey	ESD black	black	dark grey	dark grey
Surfaces	structured	smooth, silky gloss	structured	smooth, silky gloss	fine structured, dull	structured	structured
Product variants Art.-No.	9-205	9-205 ESD	9-240			9-225	9-290
	9-215	9-215 ESD	9-250			9-226	
			9-270				
Bases Art.-No.			9-251	9-251ESD	9-251 SW	9-227	9-291
			9-261	9-261ESD	9-261 SW	9-228	
			9-262		9-262 SW	9-229	
			9-281	9-281ESD	9-281 SW		SPANNFIX 4.0 With many new features!
					9-284 SW		
Heads Art.-No.			9-252	9-252 ESD			
				9-253 ESD			
				9-255 ESD			
			9-254				Find out more on the page 16 and 17!
				9-257 ESD			
Spare jaws Art.-No.	9-900-0181 ESD (single) 9-900-E50-ESD (pair)		9-900-0181 ESD (single) 9-900-E50-ESD (pair)			9-900-0766-1	9-900-0773-1
Protective jaws	Available in different versions see following page						

SPANNFIX 4.0
With many new features!

Find out more on the page 16 and 17!

All ESD versions with 10 mm grounding pushbutton