

Model No.: **GP14AU**




|                           |  |
|---------------------------|--|
| <b>NO MERCURY ADDED</b>   |  |
| <b>Description</b>        | : Mercury & Cadmium Free Alkaline Manganese Battery, C Size  |
| <b>Chemical System</b>    | : Alkaline Manganese   |
| <b>Nominal Voltage</b>    | : 1.5 Volts  |
| <b>Nominal Dimensions</b> | : $\varnothing 26.2$ mm x 50.0 mm  |
| <b>Terminals</b>          | : Protruded positive (+) and flat negative (-) contacts  |
| <b>Jacket</b>             | : Foil jacket  |
| <b>Applications</b>       | : All electronic devices, e.g. transistor radios, cassette recorders, toys, alarm clocks, lighting & torches, portable fans. |
| <b>Shelf Life</b>         | : 10 years at 20°C in a well ventilated area   |
| <b>Average Weight</b>     | : 60g  |

### Cross References:

| GP   | JIS  | IEC  | Eveready | Duracell | Varta |
|------|------|------|----------|----------|-------|
| 14AU | LR14 | LR14 | E39      | MN1400   | 4014  |

### Typical Service Life:

| Discharge Resistance | Discharge Condition | End Point Voltage | Service Life |
|----------------------|---------------------|-------------------|--------------|
| 3.9 Ohms             | 24 Hrs/ Day         | 0.9V              | 18 Hrs       |

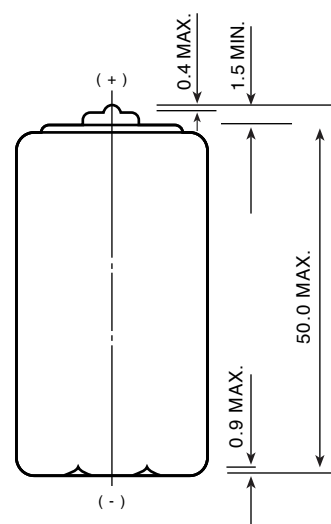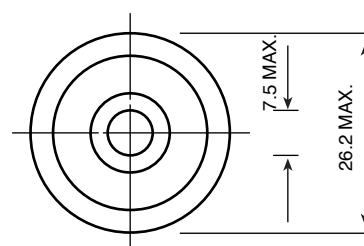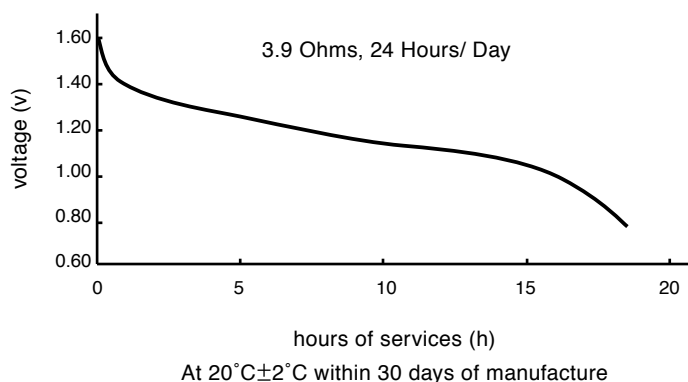

Unit : mm

The information (subject to change without prior notice) contained in this document is for reference only and should not be used as a basis for product guarantee or warranty. For applications other than those described here, please consult your nearest GP Sales and Marketing Office or Distributors.