


# NEMA TYPE 1 SINGLE-DOOR ENCLOSURES

## *SCE-LP Series*

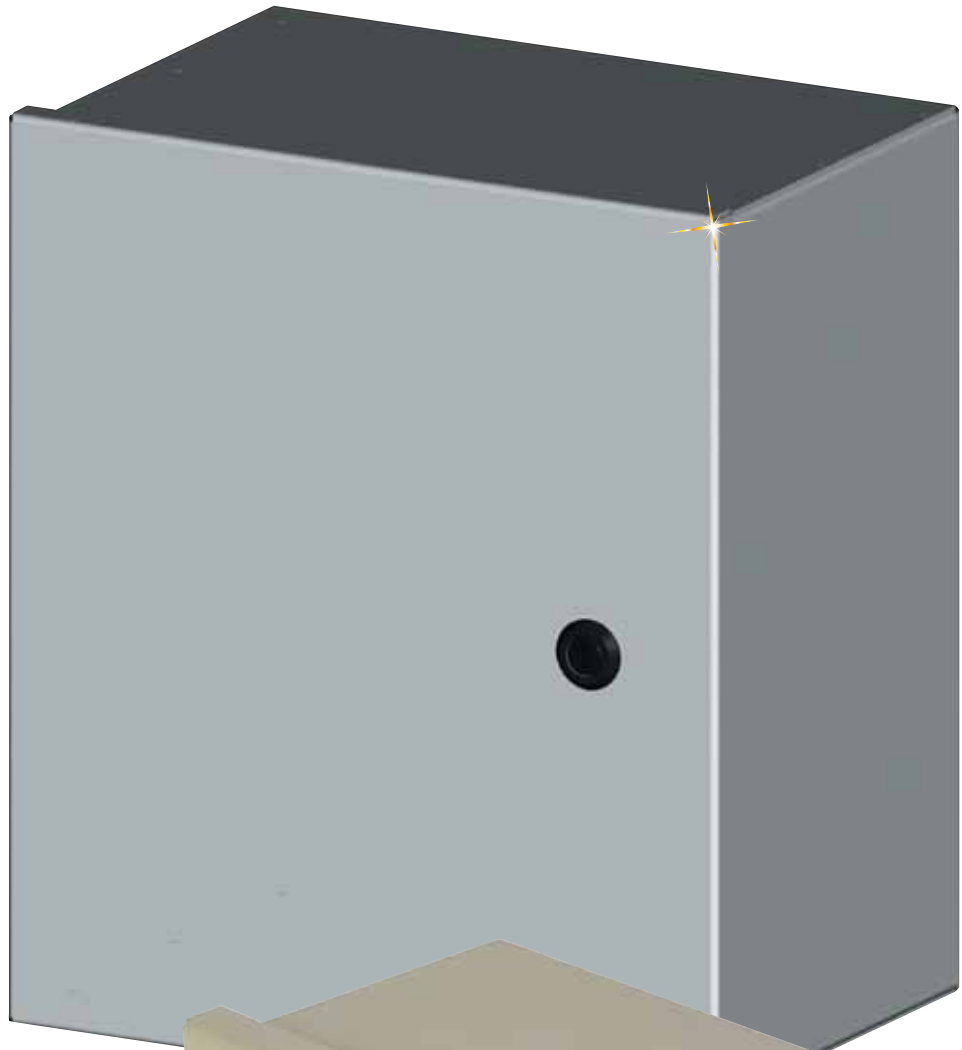

SCE-10N804LP  
shown smaller  
than actual size.

- 0.060 and 0.075" Carbon Steel Depending on its Size
- Spot Weld Construction
- Standoffs Provided for Mounting Optional Panels
- Doors Open 180°
- Black Quarter Turn Latches
- Latches Are Opened or Closed with a Screwdriver
- Ground Stud On Door
- Mounting Holes in Back of Enclosure
- Subpanel Mounting Hardware



SCE-6N604LP shown  
smaller than actual size.

### Application


Designed to house electrical controls, instruments and components in areas that do not require oil, water and dust tight protection.

### Finish

ANSI-61 gray powder coat inside and out over phosphatized surface. Optional panels are powder coated white.

### Industry Standards

NEMA Type 1  
UL Listed Type 1  
CSA Type 1  
IEC 60529 IP 30

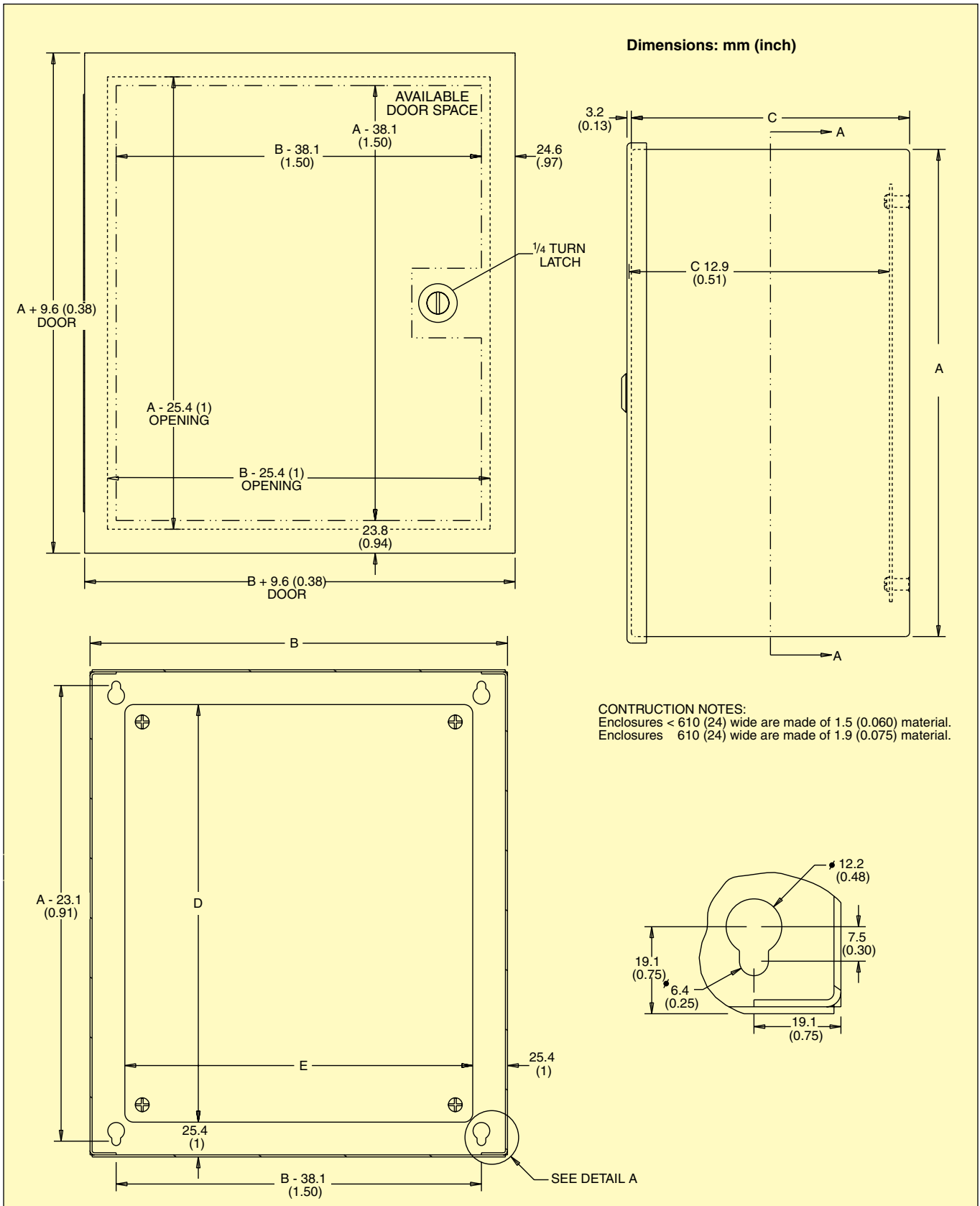

## To Order

### TYPE 1 SINGLE-DOOR ENCLOSURES

ENCLOSURES (inch)				SUB-PANEL (inch)		
MODEL NO.	HEIGHT (A)	WIDTH (B)	DEPTH (C)	MODEL NO.	HEIGHT (D)	WIDTH (E)
SCE-6N604LP	6.00	6.00	4.00	SCE-6N6MP	4.00	4.00
SCE-8N604LP	8.00	6.00	4.00	SCE-8N6MP	6.00	4.00
SCE-8N804LP	8.00	8.00	4.00	SCE-8N8MP	6.00	6.00
SCE-8N806LP	8.00	8.00	6.00	SCE-8N8MP	6.00	6.00
SCE-10N804LP	10.00	8.00	4.00	SCE-10N8MP	8.00	6.00
SCE-10N806LP	10.00	8.00	6.00	SCE-10N8MP	8.00	6.00
SCE-10N1004LP	10.00	10.00	4.00	SCE-10N10MP	8.00	8.00
SCE-10N1006LP	10.00	10.00	6.00	SCE-10N10MP	8.00	8.00
SCE-12N1004LP	12.00	10.00	4.00	SCE-12N10MP	10.00	8.00
SCE-12N1006LP	12.00	10.00	6.00	SCE-12N10MP	10.00	8.00
SCE-12N1204LP	12.00	12.00	4.00	SCE-12N12MP	10.00	10.00
SCE-12N1206LP	12.00	12.00	6.00	SCE-12N12MP	10.00	10.00
SCE-12N1208LP	12.00	12.00	8.00	SCE-12N12MP	10.00	10.00
SCE-14N1204LP	14.00	12.00	4.00	SCE-14N12MP	12.00	10.00
SCE-14N1206LP	14.00	12.00	6.00	SCE-14N12MP	12.00	10.00
SCE-14N1208LP	14.00	12.00	8.00	SCE-14N12MP	12.00	10.00
SCE-16N1206LP	16.00	12.00	6.00	SCE-16N12MP	14.00	10.00
SCE-16N1208LP	16.00	12.00	8.00	SCE-16N12MP	14.00	10.00
SCE-16N1606LP	16.00	16.00	6.00	SCE-16N16MP	14.00	14.00
SCE-16N1608LP	16.00	16.00	8.00	SCE-16N16MP	14.00	14.00
SCE-16N2006LP	16.00	20.00	6.00	SCE-20N16MP	18.00	14.00
SCE-20N1606LP	20.00	16.00	6.00	SCE-20N16MP	18.00	14.00
SCE-20N1608LP	20.00	16.00	8.00	SCE-20N16MP	18.00	14.00
SCE-20N2006LP	20.00	20.00	6.00	SCE-20N20MP	18.00	18.00
SCE-20N2008LP	20.00	20.00	8.00	SCE-20N20MP	18.00	18.00
SCE-20N2010LP	20.00	20.00	10.00	SCE-20N20MP	18.00	18.00
SCE-24N1606LP	24.00	16.00	6.00	SCE-24N16MP	22.00	14.00
SCE-24N2006LP	24.00	20.00	6.00	SCE-24N20MP	22.00	18.00
SCE-24N2008LP	24.00	20.00	8.00	SCE-24N20MP	22.00	18.00
SCE-24N2010LP	24.00	20.00	10.00	SCE-24N20MP	22.00	18.00
SCE-24N2406LP	24.00	24.00	6.00	SCE-24N24MP	22.00	22.00
SCE-24N2408LP	24.00	24.00	8.00	SCE-24N24MP	22.00	22.00
SCE-24N2412LP	24.00	24.00	12.00	SCE-24N24MP	22.00	22.00
SCE-30N2406LP	30.00	24.00	6.00	SCE-30N24MP	28.00	22.00
SCE-30N2408LP	30.00	24.00	8.00	SCE-30N24MP	28.00	22.00
SCE-30N2412LP	30.00	24.00	12.00	SCE-30N24MP	28.00	22.00
SCE-30N3008LP	30.00	30.00	8.00	SCE-30N30MP	28.00	28.00
SCE-36N2406LP	36.00	24.00	6.00	SCE-36N24MP	34.00	22.00
SCE-36N2408LP	36.00	24.00	8.00	SCE-36N24MP	34.00	22.00
SCE-36N2412LP	36.00	24.00	12.00	SCE-36N24MP	34.00	22.00
SCE-36N3006LP	36.00	30.00	6.00	SCE-36N30MP	34.00	28.00
SCE-36N3008LP	36.00	30.00	8.00	SCE-36N30MP	34.00	28.00
SCE-36N3012LP	36.00	30.00	12.00	SCE-36N30MP	34.00	28.00

Ordering Examples: SCE-6N604LP, Type 1 single-door enclosure.  
SCE-16N2006LP, Type 1 single-door enclosure, SCE-20N16MP, sub-panel.