

RF / Coaxial Cable Assembly

SMA Bulkhead Jack-to-MCX Right Angle Plug, 100mm

multicomp PRO


**RoHS
Compliant**




Electrical Performance:

Impedance	: 50Ω
Frequency Range	: DC ~ 6.0 Ghz
Working Voltage	: 170Vrms Max.
Dielectric Withstanding Voltage	: 750Vrms Max.
Insulator Resistance	: 1000MΩ Min.

Diagram



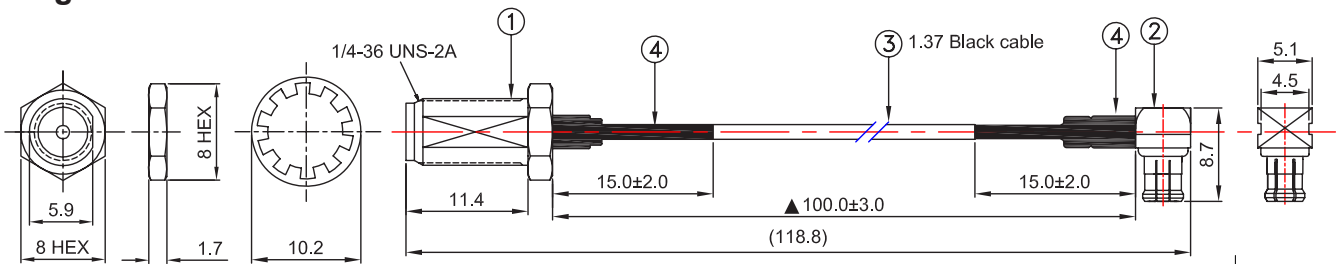


Specification	DC ~ 6.0 GHz
VSWR	1.65 : 1 Max.
Insertion Loss	-1.1 dB Max.

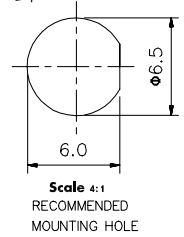

Dimensions : Millimetres

Sl.	Description	Qty
1	SMA B/H Jack Crimp for 1.37mm	1
2	MCX R/A Plug Crimp for OD 1.37mm Cable	
3	1.37mm Black Cable	
4	Heat Shrink Tube F32 Ø2.5mm L=15mm Colour: Black	

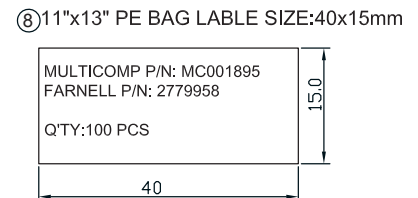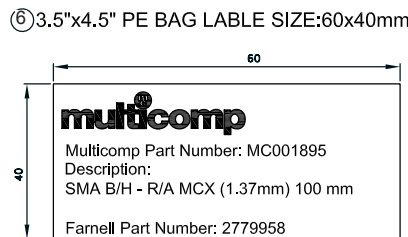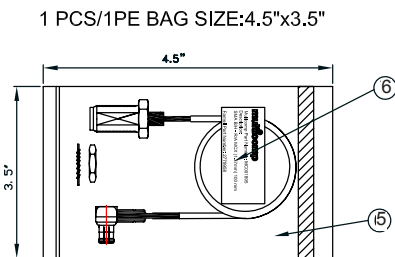

Newark.com/multicomp-pro
Farnell.com/multicomp-pro
Element14.com/multicomp-pro

multicomp PRO