

## Han 3 EMC Hood Coupler 1 Lever M20

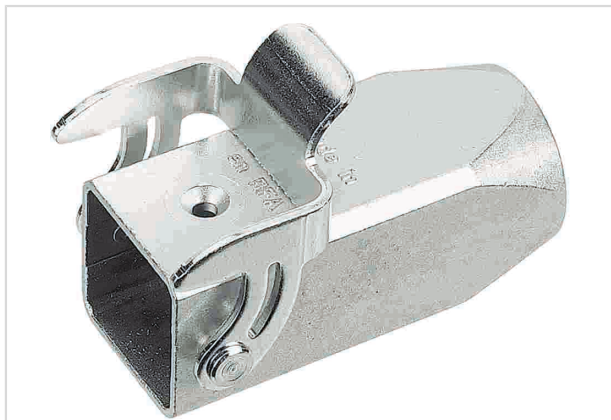


Image is for illustration purposes only. Please refer to product description.

Part number	19 62 003 1750
Specification	Han 3 EMC Hood Coupler 1 Lever M20
HARTING eCatalogue	<a href="https://b2b.harting.com/19620031750">https://b2b.harting.com/19620031750</a>

### Identification

Category	Hoods/Housings
Series of hoods/housings	Han <sup>®</sup> EMC
Type of hood/housing	Cable to cable housing

### Version

Locking type	Single locking lever
Size	3 A
Version	Top entry
Cable entry	1x M20
Field of application	Hoods/Housings for higher EMC requirements

### Technical characteristics

Limiting temperature	-40 ... +125 °C
Degree of protection acc. to IEC 60529	IP44 IP65 / IP67 with seal screw 09 20 000 9918
Type rating acc. to UL 50 / UL 50E	12

### Material properties

Material (hood/housing)	Zinc die-cast
Surface (hood/housing)	Uncoated
Colour (hood/housing)	Unpainted
Material (locking)	Steel
Surface (locking)	Zinc plated



Pushing Performance

## Material properties

RoHS	compliant with exemption
RoHS exemptions	6(a) / 6(a)-I: Lead as an alloying element in steel for machining purposes and in galvanised steel containing up to 0,35 % lead by weight / Lead as an alloying element in steel for machining purposes containing up to 0,35 % lead by weight and in batch hot dip galvanised steel components containing up to 0,2 % lead by weight
ELV status	compliant with exemption
China RoHS	50
REACH Annex XVII substances	No
REACH ANNEX XIV substances	No
REACH SVHC substances	Yes
REACH SVHC substances	Lead

## Specifications and approvals

Approvals	DNV GL
CE	Yes

## Commercial data

Packaging size	10
Net weight	70.7 g
Country of origin	Romania
European customs tariff number	85389099
eCl@ss	27440202 Shell for industrial connectors