

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2157601003

Status:


Active

Overview:

Micro-Fit+ Connector System

Description:

Micro-Fit+ Right-Angle Header, 3.00mm Pitch, Single Row, 3 Circuits, Matte Tin (Sn) Plating, UL 94V-0, Glow-Wire Capable, Black

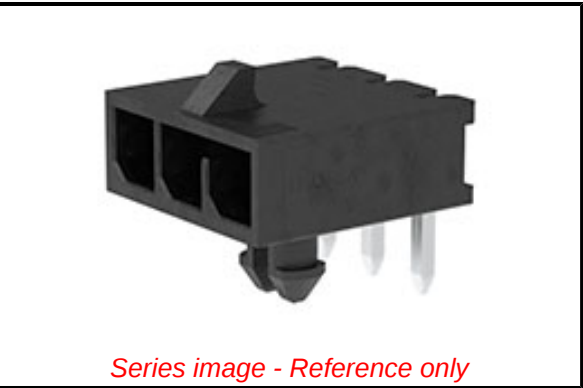

Series image - Reference only

Documents:

[Drawing \(PDF\)](#)

[Product Specification 2064600000-PS-000 \(PDF\)](#)

[Test Summary 2157590005-TS-000 \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	PCB Headers
Series	215760
Application	Power, Wire-to-Board
Overview	Micro-Fit+ Connector System
Product Name	Micro-Fit+
UPC	193264927838
Physical	
Breakaway	No
Circuits (Loaded)	3
Circuits (maximum)	3
Color - Resin	Black
Durability (mating cycles max)	25
First Mate / Last Break	No
Glow-Wire Capable	Yes
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Metal	High Copper Alloy
Material - Plating Mating	Matte Tin
Material - Resin	Liquid Crystal Polymer
Net Weight	0.570/g
Number of Rows	1
Orientation	Right Angle
PCB Thickness - Recommended	1.57mm
Packaging Type	Tray
Pitch - Mating Interface	3.00mm
Pitch - Termination Interface	3.00mm
Polarized to Mating Part	Yes
Polarized to PCB	Yes
Shrouded	Yes
Temperature Range - Operating	-40° to +105°C
Termination Interface: Style	Through Hole
Electrical	
Current - Maximum per Contact	13.0A
Voltage - Maximum	600V AC (RMS)/DC
Material Info	
Reference - Drawing Numbers	
Product Specification	2064600000-PS-000
Sales Drawing	2157600002-PK-000, 2157600003-SD-000
Test Summary	2157590005-TS-000

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2020)9139-DC (19 Jan 2021)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

215760 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION