

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [2157591008](#)
Status: **Active**
Overview: [Micro-Fit+ Connector System](#)
Description: Micro-Fit+ Receptacle Housing, Single Row, 8 Circuits, UL 94V-0, Glow-Wire Capable, Black

Documents:

[Drawing \(PDF\)](#) [Test Summary 2157590005-TS-000 \(PDF\)](#)
[Product Specification 2064600000-PS-000 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Packaging Specification 2157590003-PK-000 \(PDF\)](#)

General

Product Family	Crimp Housings
Series	215759
Application	Power, Wire-to-Board
Overview	Micro-Fit+ Connector System
Product Name	Micro-Fit+
UPC	193264921652


Physical

Circuits (maximum)	8
Color - Resin	Black
Gender	Receptacle
Glow-Wire Capable	Yes
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	0.997/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	3.00mm
Pitch - Termination Interface	3.00mm
Polarized to Mating Part	Yes
Temperature Range - Operating	-40° to +105°C

Material Info

Reference - Drawing Numbers

Packaging Specification	2157590003-PK-000
Product Specification	2064600000-PS-000
Sales Drawing	2157590002-000
Test Summary	2157590005-TS-000

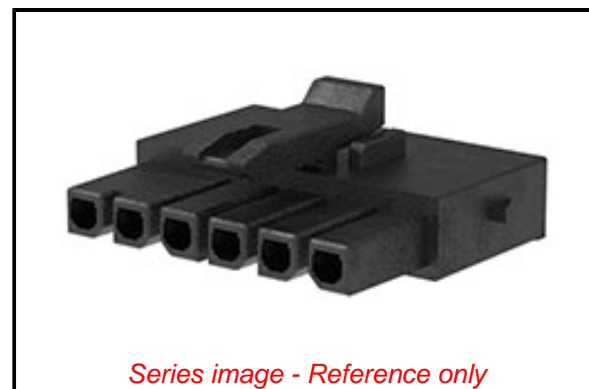

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2020)9139-DC (19
Jan 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[215759 Series](#)

Mates With

Micro-Fit+ Headers [216571](#) , [215760](#)