



Application Tooling > Spare & Wear Tooling



Applicator & Product Style: OCEAN

Features

Other

Applicator & Product Style	OCEAN
----------------------------	-------

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)



EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Candidate List Declared Against: JAN 2020 (205) SVHC > Threshold: Not Yet Reviewed
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>



Compatible Parts

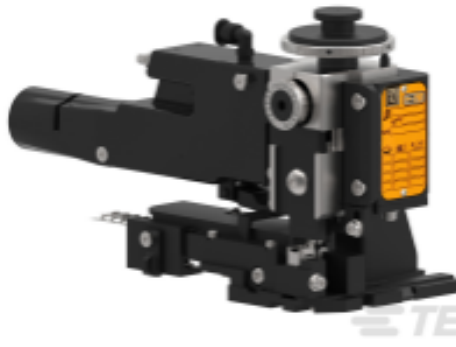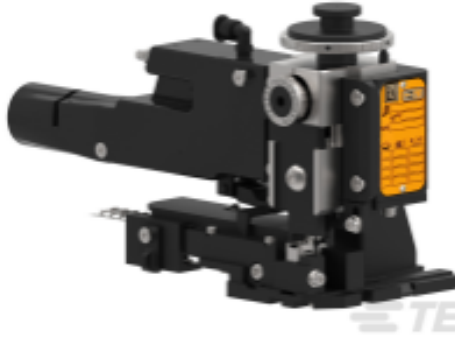 TE Part # 2151014-1 OCEAN_2.0_APPLICATOR-S-042F048O	 TE Part # 2-2151014-1 OCEAN_2.0_APPLICATOR-S-042F048O	 TE Part # 2-2151014-2 OCEAN_2.0_APPLICATOR-S-042F048O	 TE Part # 2151014-2 OCEAN_2.0_APPLICATOR-S-042F048O
 TE Part # 5-2151014-1 OCEAN_2.0_APPLICATOR-S-042F048O	 TE Part # 5-2151014-2 OCEAN_2.0_APPLICATOR-S-042F048O	 KIT TE Part # 7-2151014-7 OCEAN_2.0_SPARE_PART_KIT-042F048O	 KIT TE Part # 7-2266553-7 OC-042F048O-752-CRIMPTOOLINGKIT
 TE Part # 466242-1 HDM SMPR042F062OK	TE Part # 466918-1 APPL,SCA 9SMPR042F062O S	TE Part # 466975-1 APPL,SCA 9SMPR042F048O S	 TE Part # 1530544-6 HDI/FA SMPO.042F.062O LM CONT
 TE Part # 2151588-1 OC-AT-S-FM-042F114O-001-0213	 TE Part # 2151588-2 OC-AT-S-FA-042F114O-001-0213		


Customers Also Bought



TE Part #2-320861-1
PIDG FLANGED SPADE TONGUE
TERMINALS



TE Part #1658670-3
D-Sub Connector Contacts: Pin, Brass,
Signal, Size 22

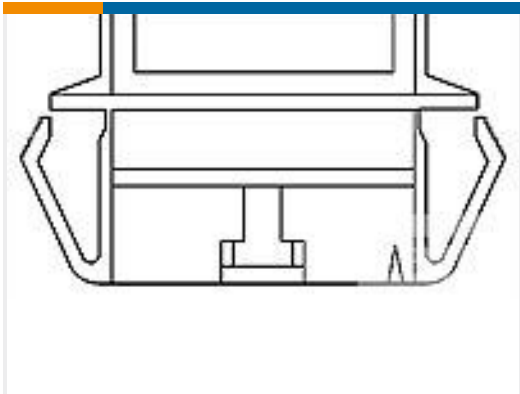


TE Part #103682-4
05 MTE PANEL MOUNT SR



TE Part #170362-3
MINI UNIVERSAL M-N-L SOCKET



TE Part #2-32589-1
PIDG SPADE TONGUE TERMINALS

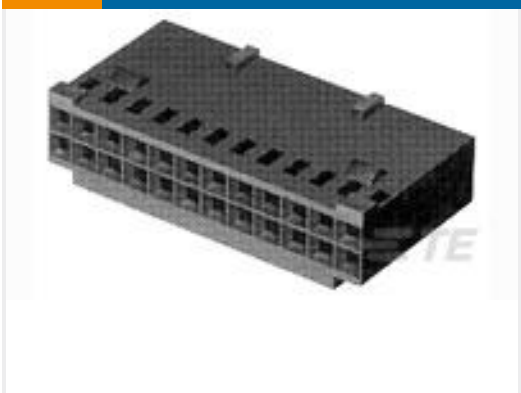


TE Part #87922-4
16 MODIV HSG W/STR RLF DR MRKD



TE Part #1-794607-2
MICRO MNL RPT CNT STRP 30AU LF



TE Part #2-1633305-2
CRIMPER, WIRE PREMIUM

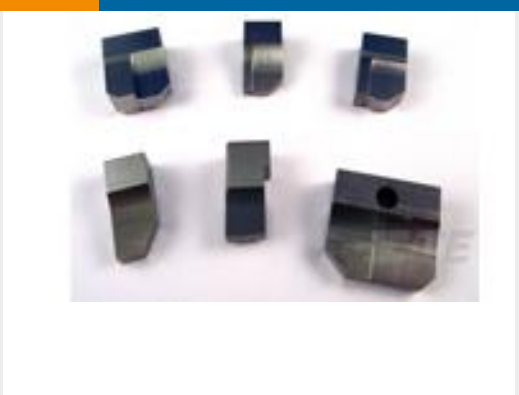

TE Part #1424333-3
ANVIL, SPECIAL



TE Part #2-683453-1
CRIMPER, INSULATION "F"(.070")

Documents

Datasheets & Catalog Pages

CRIMPING WHERE FORM MEETS FUNCTION

English

Instruction Sheets

Instruction Sheet (U.S.)

English