


Cat.5e Booted STP Patch Cables

Booted Cat.5e STP Patch Cables

This range of patch cables feature the plastic strain relief boot. Each cable is fully tested & guaranteed.

- Manufactured using quality parts - 50 micron gold shielded plugs & 26AWG UL approved stranded foil screened STP cable
- Wired to 258A specification & tested to 100 MHz frequency requirements
- Ex stock availability in 6 colours for immediate despatch, pin 1 to 1 wiring configuration
- Custom lengths available on short lead times
- Ideal for current networking requirements
- Traditional style patch cables, fully tested for purpose

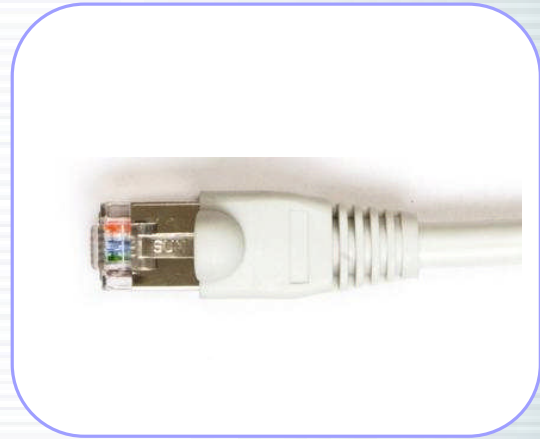

Wiring Configuration		
Pin 1	Colour	Pin 1
1	White/Orange	1
2	Orange/Whit	2
3	White/Green	3
4	Blue/White	4
5	White/Blue	5
6	Green/White	6
7	White/Brown	7
8	Brown/White	8

Length	Beige	Blue	Red	Green	Yellow	Black
1m	1962-1	1962-1B	1962-1R	1962-1G	1962-1Y	1962-1BK
2m	1962-2	1962-2B	1962-2R	1962-2G	1962-2Y	1962-2BK
3m	1962-3	1962-3B	1962-3R	1962-3G	1962-3Y	1962-3BK
5m	1962-5	1962-5B	1962-5R	1962-5G	1962-5Y	1962-5BK
10m	1962-10	1962-10B	1962-10R	1962-10G	1962-10Y	1962-10BK