

2159658-1 ✓ ACTIVE

TE Internal #: 2159658-1

Modular Twisted Pair Cable Assemblies, Not Specified, Cat 5e,

Modular Twisted Pair Cable Assembly Overall Outside Cable

Diameter 5.3 mm [.2 in]

[View on TE.com >](#)



Cable Assemblies > Copper Cable Assemblies > Mod Twisted Pair Cables



Modular Twisted Pair Cable Assembly Sales Region: **Not Specified**

Modular Twisted Pair Cable Assembly Performance Category: **Cat 5e**

Modular Twisted Pair Cable Assembly Overall Outside Cable Diameter: **5.3 mm [.2 in]**

Modular Twisted Pair Cable Assembly Shielded: **Yes**

Cable Assembly Length: **.25 m [.82 ft]**

Features

Product Type Features

Modular Twisted Pair Cable Assembly Performance Category	Cat 5e
Modular Twisted Pair Cable Assembly Shielded	Yes
Modular Twisted Pair Cable Assembly Product Type	Cable Assembly
Modular Twisted Pair Cable Assembly Connector Type (End A)	Plug
Modular Twisted Pair Cable Assembly Connector Type (End B)	RJ45

Configuration Features

Modular Twisted Pair Cable Assembly Configuration	Double-Ended
Modular Twisted Pair Cable Assembly Keyed	No

Body Features

Modular Twisted Pair Cable Assembly Color	Black
---	-------

Dimensions

Modular Twisted Pair Cable Assembly Overall Outside Cable Diameter	5.3 mm [.2 in]
Wire Size	.13 mm ²



Usage Conditions

Operating Temperature Range	-40 – 75 °C
-----------------------------	-------------

Product Availability

Modular Twisted Pair Cable Assembly Sales Region	Not Specified
--	---------------

Other

Cable Assembly Length	.25 m [.82 ft]
-----------------------	----------------

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Not Yet Reviewed
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 2100357-4
RJ POINT FIVE TO RJ45, 2.0M



TE Part # 2142759-2
Cable Assy, RJ.5 to RJ45 shielded



TE Part # 2100357-1
RJ POINT FIVE TO RJ45, 0.5M



TE Part # 2100357-2
RJ POINT FIVE TO RJ45, 1.0M



TE Part # 2100357-5
RJ POINT FIVE TO RJ45, 2.5M



 
TE Part # 2142759-1
Cable Assy, RJ.5 to RJ45 shielded



TE Part # 1-2100357-0
RJ POINT FIVE TO RJ45, 10.0M




TE Part # 1-2142759-0
Cable Assy, RJ.5 to RJ45 shielded




TE Part # 1-2159684-0
C/A, RJ45 TO RJ.5, L=10000



 
TE Part # 2100357-3
RJ POINT FIVE TO RJ45, 1.5M



 
TE Part # 2142759-3
Cable Assy, RJ.5 to RJ45 shielded



 
TE Part # 2142759-4
Cable Assy, RJ.5 to RJ45 shielded



 
TE Part # 2142759-6
Cable Assy, RJ.5 to RJ45 shielded



 TE Part # 2142759-9
Cable Assy, RJ.5 to RJ45 shielded



 TE Part # 2159658-4
C/A, RJ.5 TO RJ45 FEMALE CAT 5E, 250MM,




TE Part # 2159684-2
C/A, RJ45 TO RJ.5, L=1000



TE Part # 2159684-6
C/A, RJ45 TO RJ.5, L=3000




 TE Part # 2159684-8
C/A, RJ45 TO RJ.5, L=5000



TE Part # 2159684-9
C/A, RJ45 TO RJ.5, L=7500

Customers Also Bought

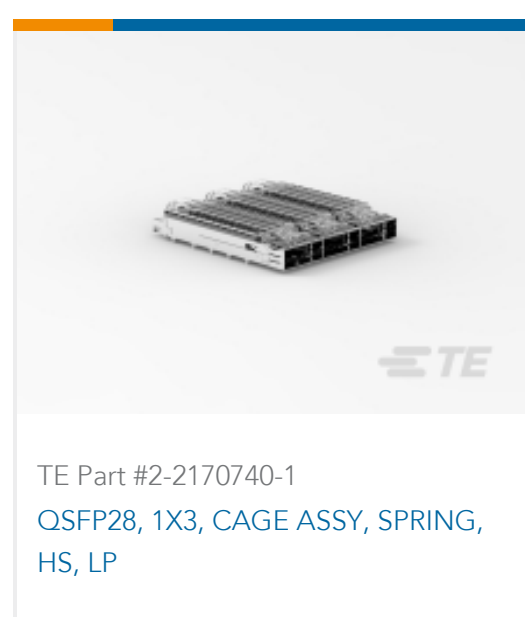

Documents

Product Drawings

C/A, RJ.5 TO RJ45 FEMALE CAT 5E, 250MM

English

CAD Files

3D PDF

3D

Customer View Model

[ENG_CVM_CVM_2159658-1_D.2d_dxf.zip](#)

English

Customer View Model

[ENG_CVM_CVM_2159658-1_D.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_2159658-1_D.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages



[RJ_POINT_FIVE_CONNECTOR_SYSTEM_QUICK_REF_GUIDE](#)

English