

5V 2A USB EURO POWER SUPPLY



TIGER PART: TGR-USB-2A-EU

Features:

- Built in Over Current and Short Circuit Protections
- Universal 100-240vac input voltage
- Supplied complete with 4 Interchangeable AC pins
- Level VI efficiency
- Approved to latest EN 62368-1 safety standards
- Ultra compact design



The Tiger Power range of switch mode power supplies feature full safety approvals to latest 62368-1 standards and also level VI energy efficiency requirements. The TGR-USB-2A-EU 5vdc 2A amp Euro USB model provides a reliable constant voltage output at up to 10 Watts continuous, suitable for a charging a comprehensive range of devices and a wide range of applications.

Part number (No cable included):	TGR-USB-2A-EU
Part number (Supplied with 1M Micro USB cable) :	TGR-USB-2A-EU
Part number (Supplied with 2M Micro USB cable):	TGR-USB-2A-EU
Input voltage:	100-240vac (90-264vac max.)
Input frequency:	47 - 63Hz
Output voltage:	5vdc
Current:	2A
Power :	10 Watts
Protection:	Short Circuit, Over Current protection
Dimensions:	59.3 x 35.9 x 21.5mm (excluding pins)
Weight:	37g (body only)
Standby Power Consumption :	0.075W max.
Minimum load:	0.0A
DC connector:	USB Type A Socket
Polarity:	Pin out suitable for wide range of charging applications
Efficiency:	78.7% Average
Input current RMS Max.:	0.2A
Inrush Current at 230vac:	40A max.
Load regulation:	+ / - 5%
Safety approval:	62368-1
M.T.B.F:	50,000 hours
Operating temperature:	0°C to + 40°C

TIGER POWER PRODUCTS – QUALITY & RELIABILITY


This specification is not for general release or circulation. Tiger Power reserves the right to make changes to spec. or product without notice or liability.

5V 2A USB EURO POWER SUPPLY



TIGER PART: TGR-USB-2A-EU

Dimensions:

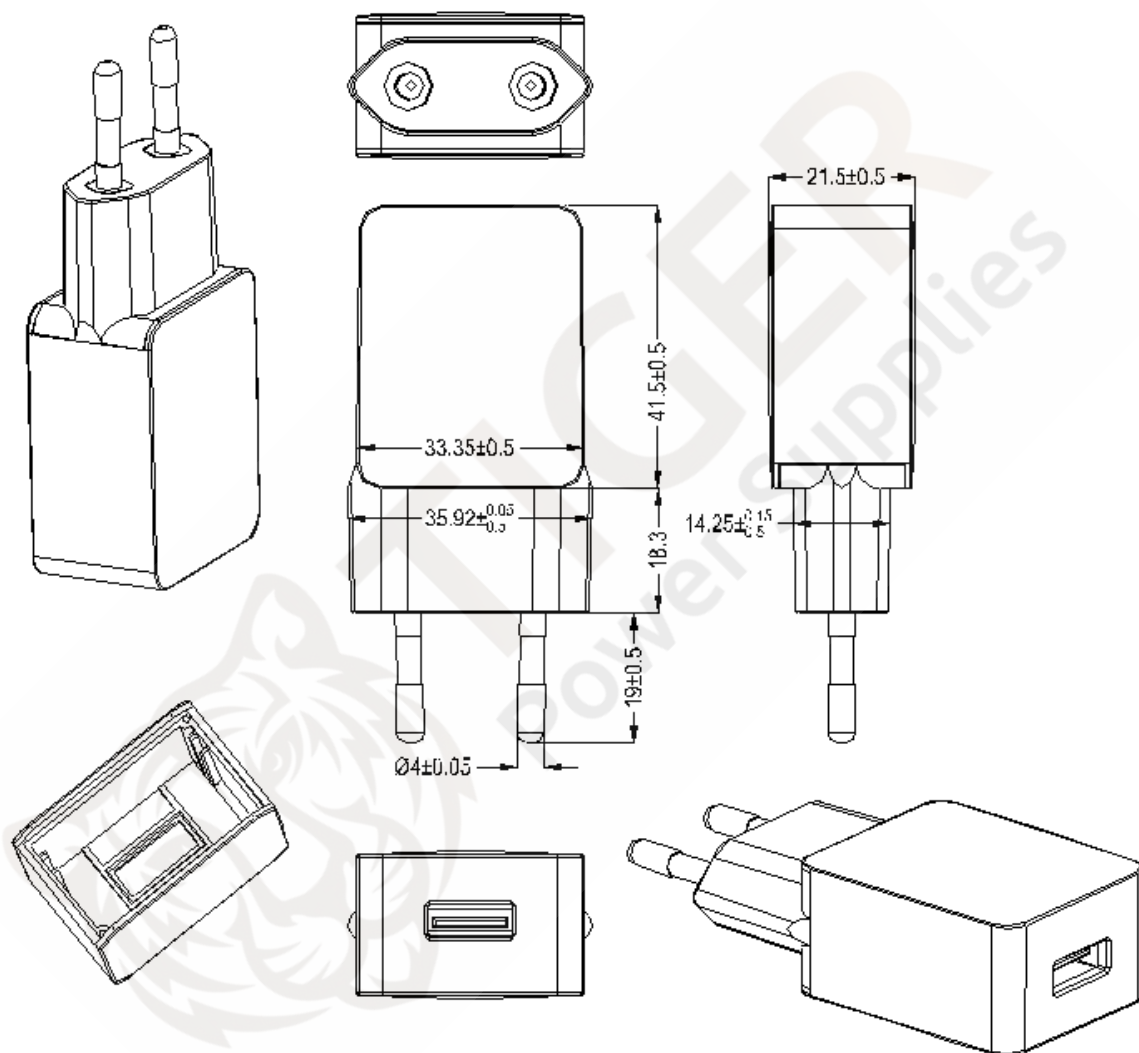

TIGER POWER PRODUCTS – QUALITY & RELIABILITY

This specification is not for general release or circulation. Tiger Power reserves the right to make changes to spec. or product without notice or liability.