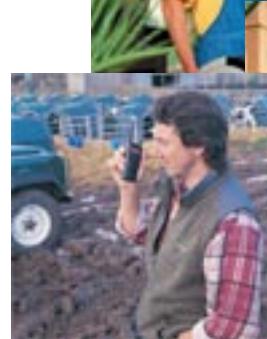# XTNi / XTNiD
TWO WAY WALKIE TALKIE RADIOS

Package Contents -
Radio
Rechargable Battery
Drop in Charger Tray
Power Supply Unit
Belt Clip
Manual
R&TTE Leaflet

Basic Information:

Nomenclature:	XTNi / XTNiD	Colour: Black	Freq Band: PMR446	Tx power: 500mW
Type Designation:	XTNi /XTNiD	Bandwidth: 12.5Khz	Channels: 8	Weight: TBA
		Range: 8 Km	Codes: 39 (An) + 83 (Dig)	Size: TBA
XTNi Tanapa No:	IXUE1032A	XTNiD Tanapa No:	IXUE1031A	
XTNi Model No:	P14XTA03A1AJ	S/T No: IXUE2044A	EAN Number:	0723755540255
XTNiD Model No:	P14XTA03A1AH	S/T No: IXUE2043A	EAN Number:	0723755540248

Mechanical:

2 pin accessory connector	Battery Meter (XTNiD)	Backlit Display (XTNiD)	Keypad Lock
Cast Metal Chassis	IP55	Signal Strenth Ind. (XTNiD)	Belt Clip
Tri Colour LED	MIL Std 810	16 Channel select knob (XTNi)	Volume

Features:

Scan, VoX with accessory,   iVoX without accessory,   Voice Scrambling,   Nuisance delete,   Cloning (via charger or MUC),
Automatic power save, Programming mode, Time out timer (can be disabled),   Computer programmable channel aliasing
(XTNiD)

Alerts:

Channel Busy/Heartbeat/Transmit LED	Low battery alert (audible)	3 call tones (+ off)	Keypad tones
Talk confirmation tone/Roger beep			

Charging:

Recharge compatible (with charger)   Standard (1100mAh) or High cap (2200 mAh) LiIon battery
 Alkaline battery capable using optional pack

Battery Life (Typical):

LiIon 1100 mAh - 12hrs / 16hrs (with "battery save" on)   LiIon 2200 mAh - 24hrs / 32hrs (with "battery save" on)
Alkaline batteries - 35hrs with premium cells

Accessories:

Accessories:	Part No:	EAN:
Replacement Charger tray	IXPN4019AR	0723755540347
Replacement High Cap Battery	RLN6305A	0723755540088
Replacement Standard Battery	RLN6351A	0723755540170
Alkaline Pack`	RLN6306A	0723755540095
Replacement Belt Clip	RLN6307A	0723755540101
Multi Unit Charger	IXPN4020AR	0723755540262
USB programming Cable & CPS CD	IXEN4007AR	0723755540279
R2R Cloning Cable	RLN6303A	0723755540065
Leather carry case	RLN6302A	0723755540057