


ELECTRICIANS TERMINAL SCREWDRIVERS

	Cat. No.	Handle Size MM	Basic Blade Size MM	Dia. Over Insulation MM	Total Length MM	Weight	
	108-000	IT18/3	75x13	75x3	5	150	19
	108-001	IT18/4	75x13	100x3	5	175	20

Both fluted handle - parallel blade

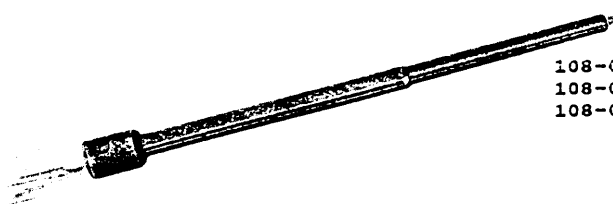

ELECTRICIANS SCREWDRIVERS

	108-002	P500/3	75x19	75x5	8	140	40
	108-003	P500/6	75x19	152x5	8	227	55
	108-004	P500/8	75x19	203x5	8	279	65

All fluted handle - parallel blade




ENGINEERS SCREWDRIVERS

	108-005	IT501/4	90x25	102x6	11	190	87
	108-006	IT502/6	102x25	152x8	13	254	143
	108-007	IT503/8	114x32	203x10	14	317	260
	108-008	IT503/10	114x32	254x10	14	368	300

All fluted handle B.S. Pattern

IMPORTANT NOTE

All engineers screwdrivers are available with completely parallel blades when

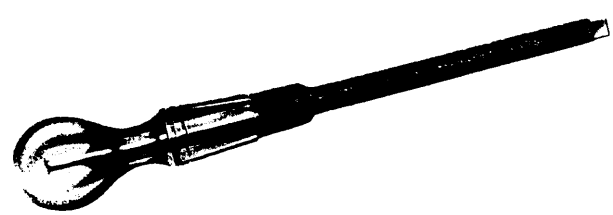

ENGINEERS CABINET HANDLE SCREWDRIVERS

	108-009	IT14/5	100x38	125x6	8	225	97
	108-010	IT516/4	127x44	102x8	13	229	165
	108-011	IT 516/6	127x44	152x8	13	279	195
	108-012	IT 38/8	152x51	203x10	14	356	335

Parallel blades allow the best sight line for locating recessed or countersunk screw heads



POZIDRIV SCREWDRIVERS

	108-013	IT/PX1/3	75x19	75x5	No 1 point	6	150	40
	108-014	IT/PX2/4	90x25	100x6	No 2 point	8	190	85
	108-015	IT/PX3/6	100x25	150x8	No 3 point	12	250	137