

AT5.5X300 | AT - PROTWIST® screwdrivers for slotted head screws - milled blades




Standards:

NF ISO 2380-1, NF ISO 2380-2, ISO 2380-1, ISO 2380-2, DIN ISO 2380-1, DIN ISO 2380-2, ASME B107.600

Description:

- Round shank for access in holes.
- Extra-long shank up to 300 mm for difficult and remote access.
- Inline Hardening Process – +100% Tip Life and +100% Bar Strength.
- Handle Material - Softer for more Comfort and still Chemical Resistant.
- Blade " tri-coating " treatment (Zinc-Nickel-Chromium) - 4x Corrosion Resistance.
- Handle 'Channel' - +10% Torque.
- Laser Marking - gives virtually Permanent Marking.
- CNC tip machining - gives better Screw Fit increasing Torque Transfer and Reducing Wear.

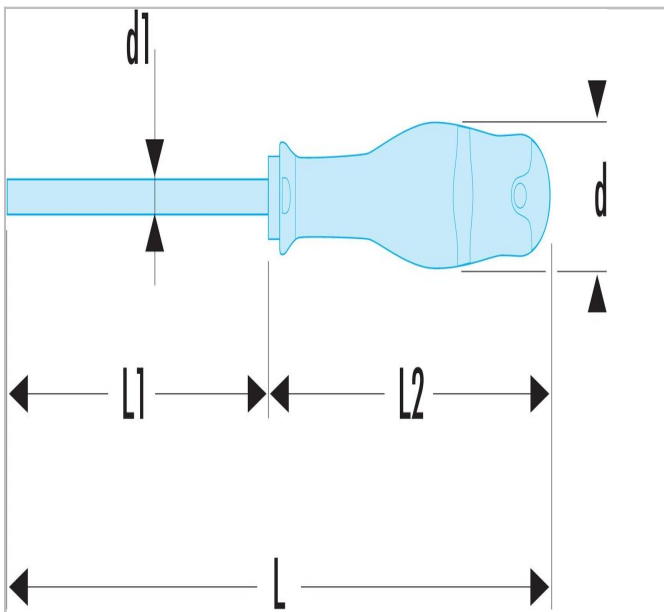

|  | AT5.5X300 |
|--|-----------|
| A [mm] | 5.5 |
| Diameter [mm] | 30.0 |
| Diameter D1 [mm] | 5.5 |
| Length L1 [mm] | 300.0 |
| Length L [mm] | 409.0 |
| Length L2 [mm] | 109.0 |
| Thickness E [mm] | 1.0 |
| Width [mm] | 5.5 |
| Weight [g] | 130.0 |