

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2175102121

Status:


Active

Overview:

Off-the-Shelf Pre-Crimped Leads

Description:

Pre-Crimped Lead L1NK 250 Female-to-L1NK 250 Female, Tin (Sn) Plating, 75.00mm Length, 22 AWG, Red

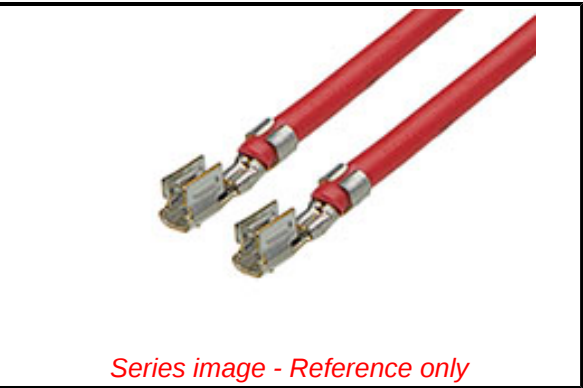

Documents:

[Drawing \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

[Datasheet \(PDF\)](#)

General	
Product Family	Cable Assemblies
Series	217510
Assembly Configuration	Pre-crimped Lead Only
Connector to Connector	L1NK 250 Crimp Terminals
Overview	Off-the-Shelf Pre-Crimped Leads
Product Name	L1NK 250
UPC	195842119451
Physical	
Cable Length	75.00mm
Circuits (Loaded)	1
Color - Resin	Red
Gender	Female-Female
Material - Metal	Copper Alloy
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	PVC
Net Weight	0.556/g
Packaging Type	Bag
Single Ended	No
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.42mm-1.60mm
Wire Size AWG	22
Wire/Cable Type	UL 1569
Electrical	
Current - Maximum per Contact	6.5A
Voltage - Maximum	250V AC (RMS)/DC
Material Info	
Reference - Drawing Numbers	
Sales Drawing	2175102121-000

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - D(2021)4569-DC (8 July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit

Contact US

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

217510 Series

Use With

L1NK 250 Receptacle Housing 207841

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION