


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [2143720001](#)
Status: **Active**
Overview: Mini-Fit Family Power Connectors
Description: Mini-Fit Sigma Sealed Hybrid Plug Housing, Dual Row, 4.20mm Pitch, 16 Circuit Footprint, 2-4-6 Circuit Configuration, UL94V-0, Natural

Documents:

Drawing (PDF)	Test Summary 2070170000-TS-000 (PDF)
Product Specification 2070170000-PS-000 (PDF)	Datasheet (PDF)
Application Specification 2070170000-AS-000 (PDF)	RoHS Certificate of Compliance (PDF)
Packaging Specification 2070170000-PK-000 (PDF)	

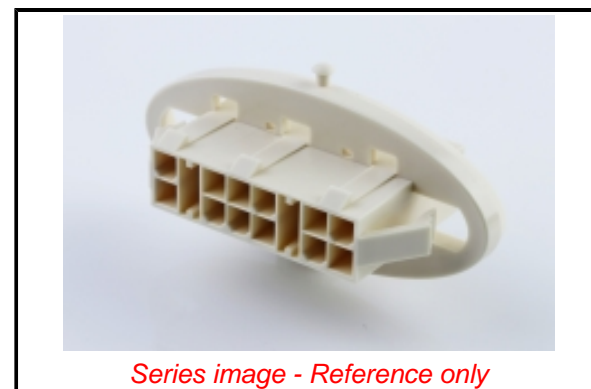

Series image - Reference only

General

Product Family	Crimp Housings
Series	214372
Application	Power, Wire-to-Wire
Overview	Mini-Fit Family Power Connectors
Product Name	Mini-Fit Sigma
UPC	193264550555

Physical

Circuits (maximum)	16
Color - Resin	Natural
Gender	Plug
Glow-Wire Capable	No
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	8.161/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	Yes
Pitch - Mating Interface	4.20mm
Pitch - Termination Interface	4.20mm
Polarized to Mating Part	Yes
Temperature Range - Operating	-40° to +105°C

Material Info

Reference - Drawing Numbers

Application Specification	2070170000-AS-000
Packaging Specification	2070170000-PK-000
Product Specification	2070170000-PS-000
Sales Drawing	2143720000-SD-000
Test Summary	2070170000-TS-000

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[214372](#) Series

Mates With

Mini-Fit Jr. Receptacle Housing [5557](#) ,
[46992](#) . Mini-Fit TPA2 Receptacle Housing
[172708](#)

Use With

Mini-Fit Sigma Sealed Cap [2070190016](#) .
Mini-Fit TPA2/Sigma Male Crimp Terminal
[172765](#) , [203070](#)