

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

**Part Number:** [0150161063](#)  
**Status:** **Active**  
**Overview:** [FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers](#)  
**Description:** 0.50mm Pitch Premo-Flex One-Touch FFC Jumper with Ears, Same Side Contacts (Type A), 152.00mm Cable Length, Gold (Au) Plating, 35 Circuits

**Documents:**

|                                                           |                                                      |
|-----------------------------------------------------------|------------------------------------------------------|
| <a href="#">Drawing (PDF)</a>                             | <a href="#">Datasheet (PDF)</a>                      |
| <a href="#">Product Specification 150160001-000 (PDF)</a> | <a href="#">RoHS Certificate of Compliance (PDF)</a> |

**General**

|                         |                                                                           |
|-------------------------|---------------------------------------------------------------------------|
| Product Family          | Cable                                                                     |
| Series                  | <a href="#">15016</a>                                                     |
| Crimp Quality Equipment | Yes                                                                       |
| Overview                | <a href="#">FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers</a> |
| Product Name            | Premo-Flex FFC Jumper                                                     |
| UPC                     | 195842135598                                                              |

**Physical**

|                               |                 |
|-------------------------------|-----------------|
| Cable Length                  | 152.00mm        |
| Circuits (Loaded)             | 35              |
| Contact Layout Type           | A (same side)   |
| Material - Plating Mating     | Gold            |
| Packaging Type                | Bag             |
| Pitch - Mating Interface      | 0.50mm          |
| Temperature Range - Operating | -40° to +105°C  |
| Wire Size AWG                 | N/A             |
| Wire/Cable Type               | Flat Flex Cable |


**Electrical**

|                               |      |
|-------------------------------|------|
| Current - Maximum per Contact | 0.3A |
| Voltage - Maximum             | N/A  |

**Material Info**

**Reference - Drawing Numbers**

|                       |               |
|-----------------------|---------------|
| Product Specification | 150160001-000 |
| Sales Drawing         | 150160001-001 |

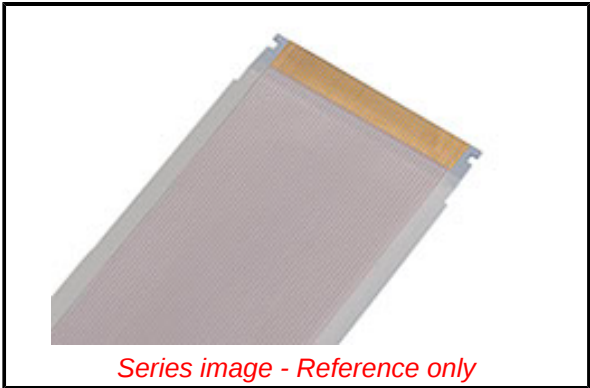

Series image - Reference only

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**  
**REACH SVHC**

Not Contained Per -  
D(2021)4569-DC (8  
July 2021)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

**China RoHS**

|                 |               |
|-----------------|---------------|
| China ROHS      | Green Image   |
| ELV             | Not Relevant  |
| RoHS Phthalates | Not Contained |

**Search Parts in this Series**

[15016](#) Series

**Mates With**

Easy-On FFC/FPC One-Touch Connector  
[2004850435](#) , [2004850535](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION