

KERN DE 15K0.2D

The long lasting story of success with dust and spray protected display device



Environmental conditions

| | |
|--------------------------------|-------|
| Maximum humidity: | 80 % |
| Maximum operating temperature: | 35 °C |
| Minimum ambient temperature: | 5 °C |

Power supply

| | |
|---------------------------------|-------------------------|
| Battery: | 9 V Block |
| Charging time: | 10 h |
| Input voltage: | 220 V - 240 V AC 50 Hz |
| Mains adapter: | Mains adapter external |
| Mains adapter/adaptor included: | EURO CH UK US |
| Operating time: | 12 h |
| Operating time (Backlight off): | 30 h |
| Operating time (Backlight on): | 15 h |
| Rechargeable battery: | Rchrg. battery optional |

Services (optional)

Adjustment at the location of installation: 961-248

| | |
|--------------------|---------|
| DAkkS Certificate: | 963-128 |
|--------------------|---------|

Category

| | |
|-----------|----------|
| Brand: | KERN |
| Category: | Balances |

Packaging & shipping

| | |
|-------------------------------|--------------------|
| Delivery: | 24 h |
| Dimensions packaging (WxDxH): | 530 x 417 x 160 mm |
| Gross weight: | 8,700 kg |
| Net weight: | 4 kg |
| Shipping method: | Parcel service |

Construction

| | |
|---------------------------------------|-------------------|
| Cable length of display device: | 1 m |
| Dimensions of display device (WxDxH): | 225 x 110 x 45 mm |
| Dimensions of weighing plate (WxDxH): | 318 x 308 x 88 mm |
| Material weighing plate: | stainless steel |
| Weighing surface (WxD): | 315 x 305 mm |

Measuring system

| | |
|---|--|
| Adjustment options: | External calibration |
| Linearity: | 800 mg 2000 mg |
| Readability [d]: | 200 mg 500 mg |
| Recommended adjusting weight: | 15 kg (F2) |
| Repeatability: | 200 mg 500 mg |
| Resolution: | 30 30.000 |
| Stabilisation time under laboratory conditions: | 2,500 s |
| Tare range: | 15 kg |
| Warm up time: | 2 h 2 h |
| Weighing capacity [Max]: | 6 kg 15 kg |
| Weighing system: | Strain gauge |
| Weighing units: | tl (HK) tol g mo lb dwt ffa oz tl (Tw) kg ozt |

Display

| | |
|-------------------------------|----------|
| Display digit height (large): | 2,500 cm |
|-------------------------------|----------|

Counting

| | |
|--|--------|
| Counting resolution: | 37500 |
| Minimum piece weight at piece counting (Laboratory): | 400 mg |
| Minimum piece weight at piece counting (Normal): | 4 g |

Functions

| | |
|--|-----|
| Counting function: | yes |
| Percentage determination: | yes |
| Vibration-free weighing (Animal weighing program): | yes |


KERN DE 15K0.2D



The long lasting story of success with dust and spray protected display device

Piktogramme

STANDARD

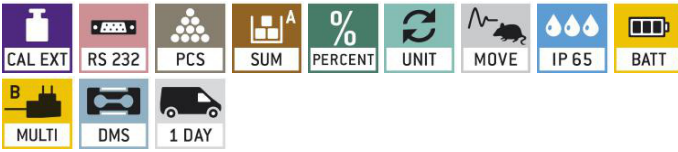

OPTION

