


KERN EOB60K20L

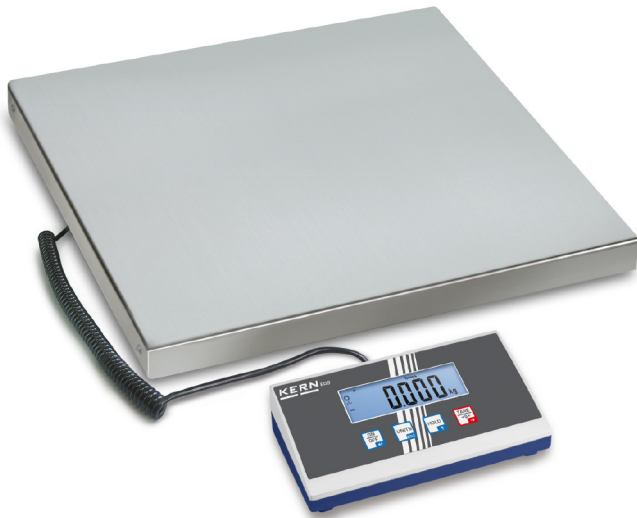

Allround parcel scale with robust stainless steel weighing plate - also with XL platform and large weighing ranges



Measuring system

Adjustment options:	External calibration
Linearity:	40 g
Readability [d]:	20 g
Recommended adjusting weight:	40 kg (M2)
Repeatability:	20 g
Resolution:	3000
Stabilisation time under laboratory conditions:	3 s
Tare range:	60 kg
Warm up time:	10 min
Weighing capacity [Max]:	60 kg
Weighing system:	Strain gauge
Weighing units:	lb kg PCS

Display

Display digit height (large):	2,500 cm
-------------------------------	----------

Functions

Data hold function:	yes
Vibration-free weighing (Animal weighing program):	yes

Environmental conditions

Maximum humidity:	80 %
Maximum operating temperature:	35 °C
Minimum ambient temperature:	5 °C

Power supply

Battery:	4x1.5 V AA
Input voltage:	100 V - 240 V 50 / 60 Hz
Mains adapter:	Mains adapter external
Mains adapter/adaptor included:	EURO CH UK US
Operating time:	60 h

Services (optional)

Adjustment at the location of installation: 961-249

DAkkS Certificate:	963-129
--------------------	---------

Category

Brand:	KERN
Category:	Balances

Packaging & shipping

Delivery:	24 h
Dimensions packaging (WxDxH):	670 x 600 x 85 mm
Gross weight:	15,600 kg
Net weight:	12,220 kg
Shipping method:	Parcel service

Construction

Cable length of display device:	2,700 m
Casing material:	Plastic
Dimensions of display device (WxDxH):	235 x 114 x 51 mm
Dimensions of weighing plate (WxDxH):	550 x 550 x 58 mm
Material weighing plate:	stainless steel
Revolving screw feet:	yes

Piktogramme

STANDARD



OPTION

