


KERN UIB 1.5T-4

Pallet scale with steel load support (IP67) und the best price-to-performance ratio

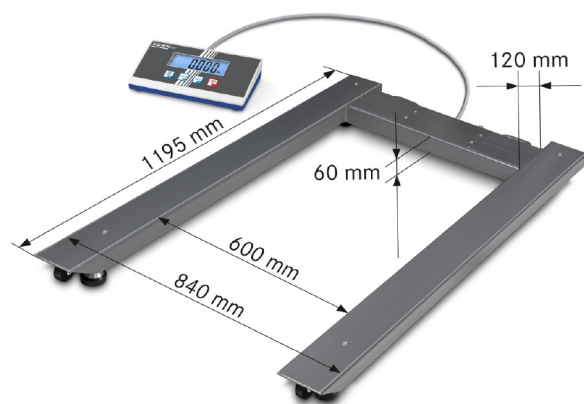

Measuring system

Adjustment options:	External calibration
Linearity:	1,500 kg
Load cell connection:	4-wire
Readability [d]:	500 g
Recommended adjusting weight:	1500 kg (M2)
Repeatability:	500 g
Resolution:	3000
Stabilisation time under laboratory conditions:	4 s
Tare range:	-1,500 t
Warm up time:	10 min
Weighing capacity [Max]:	1,500 t
Weighing system:	Strain gauge
Weighing units:	lb kg PCS

Display

Display digit height (large):	2,500 cm
-------------------------------	----------

Functions

Data hold function:	yes
---------------------	-----

Environmental conditions

Maximum humidity:	95 %
Maximum operating temperature:	40 °C
Minimum ambient temperature:	-10 °C
Minimum humidity:	10 %

Power supply

Battery:	4x1.5 V AA
Input voltage:	100 V - 240V AC 50/60Hz 0.3A
Mains adapter:	Mains adapter external
Mains adapter/adaptor included:	EURO UK US
Operating time:	60 h

Services (optional)

Adjustment at the location of installation: 961-250

DAkkS Certificate: 963-130

Category

Brand:	KERN
Category:	Balances
Product Group:	Pallet scale

Packaging & shipping

Delivery:	48 h
Dimensions packaging (WxDxH):	1270 x 900 x 260 mm
Gross weight:	87 kg
Net weight:	51 kg
Shipping method:	Freight forwarder

Construction

Cable length:	5 m
Cable length of display device:	5 m
Dimensions of display device (WxDxH):	260 x 115 x 70 mm
Dimensions of weighing plate (WxDxH):	1195 x 840 x 110 mm
Level indicator:	yes
Revolving screw feet:	yes
Wall mount:	yes
Weighing surface (WxD):	1195 x 840 mm

Piktogramme

STANDARD



OPTION

