



PIR Presence Detectors & Lighting Controls



**Ideal
for energy
saving in the
workplace!**



Timeguard's new PIR Presence Detectors bring economy and flexibility to the workplace. Lights are activated only when they are needed, saving money and CO₂ when areas are unoccupied.

Take control of your lighting with our PIR light controllers and security light switches. Save more than money with Timeguard!



Reduce CO₂ Emissions

Save Energy

Save Money

Easy to Install

**Comply with Part L
of Building Regs.**



PIR Presence Detectors & Lighting Controls

PIR Presence Detectors & Lighting Controls

IP55
RATING

IP55
RATING



SLFM360
360° Flush Mount Ceiling Presence Detector



SLW360
360° Surface Mount Ceiling Presence Detector



SLW2400
2400W PIR Light Controller



TLW3000
3000W PIR Multi Light Controller



PDFM361/PDFM362
PIR Presence Detector - Flush Mount



PDSM361/PDSM362
PIR Presence Detector - Surface Mount



IR10
IR Remote Control



200.0.000
PIR PresenceLight 360
(Surface Box 907.0.513 available)



201.0.090
PIR Compact Passage 360
(Surface Box 907.0.514 available)

Cat No.

	PIR Presence Detectors & Lighting Controls	Time	Lux	Range	Load*
SLFM360	360° Flush Mount Ceiling PIR Light Controller	✓	✓		2000W (i) 500W (f)
SLW360	360° Surface Mount Ceiling PIR Light Controller	✓	✓		2000W (i) 500W (f)
SLW2400	2400W PIR Light Controller	✓	✓		2000W (i) 500W (f)
MTLW3000	3000W PIR Multi Light Controller	✓	✓		3000W (i) 600W (f)
PDFM361	PIR Presence Detector - Flush Mount	✓	✓	✓	2000W (i) 750W (f)
PDFM362	PIR Presence Detector - Flush Mount, 2 Channel	✓ x2	✓	✓	2000W (i) 750W (f)
PDSM361	PIR Presence Detector - Surface Mount	✓	✓	✓	2000W (i) 750W (f)
PDSM362	PIR Presence Detector - Surface Mount, 2 Channel	✓ x2	✓	✓	2000W (i) 750W (f)
IR10	IR Remote Control - for use with PIR Presence Detectors				
200.0.000	PIR PresenceLight 360 - (Surface Box 907.0.513 required)	✓	✓		1200W (i) 500W (f)
201.0.090	PIR Compact Passage - (Surface Box 907.0.514 required)	✓	✓		1200W (i) 500W (f)
907.0.513	Surface Box for PresenceLight 360 (200.0.000)				
907.0.514	Surface Box for Compact Passage 360 (201.0.090)				
Security Light Switches					
ZV210	Programmable Single Gang Security Light Switch				
ZV215	Programmable Double Gang Security Light Switch				
FLA01	Fluorescent Strip Light Adaptor				
ZV700	7 Day Digital Security Light Switch				
ZV810	Motion Sensor PIR Light Switch				
PSL07	Dusk/Dawn/Random Low Energy Lamp Holder				
PSL118	Automatic Dusk to Timed OFF Lamp Holder				
RLS010	Infra-Red Light Switch with Remote Control				
DS1	Electronic Time Delay Switch - 2 Wire				
DS2	Electronic Time Delay Switch - 3 Wire				
DSS	Delay Switch Slave				

*Load: (i) = Incandescent, (f) = Fluorescent/Low Energy

Security Light Switches



ZV700
7 Day Digital Security Light Switch



ZV810
Motion Sensor PIR Light Switch



ZV210/ZV215
Programmable Security Light Switch



RLS010
Infra-Red Light Switch with Remote Control



DS1/DS2/DSS
Electronic Time Delay Switch



PSL07
Low Energy Lamp Holder



PSL118
Dusk to Timed Off Lamp Holder



Time & Heating Controllers

Plug-in Time Controllers



TS830/TS840



TS800/TS820



ETU11/ETU17



ET03



ET05



TG85

Immersion Heater Controllers



TS930



TS900



ETU2000/ETU8000



CTS960



CTU9000

Cat No.

	Plug-in Time Controllers
TS800	24hr Plug-in Time Controller
TS820	7 day Plug-in Time Controller
TS830	24hr Segment Plug-in Time Controller
TS840	7 day Segment Plug-in Time Controller
ETU11	24hr Digital Plug-in Time Controller
ETU17	7 day Digital Plug-in Time Controller
TG85	Dusk to Dawn Timeswitch
ET03	7 Day Electronic Timeswitch
ET05	Plug-in Thermostat
TS900	24hr Immersion Heater Timeswitch
TS930	24hr Segment Immersion Heater Timeswitch
CTS960	24hr Compact Segment Immersion Heater Time Controller
CTU9000	24hr/7 day Compact Digital Immersion Heater Time Controller
ETU2000	24hr Electronic Immersion Heater Timeswitch
ETU8000	7 day Electronic Immersion Heater Timeswitch
	Nightlights
EPNL5	Automatic Dusk to Dawn Nightlight
EPNL5T	Dusk to Dawn Nightlight – Twin pack
EPNLB	Spare Night Light Bulbs
TGNL15	Cool Glow Night Light
TGNL15T	Cool Glow Night Light – Triple Pack
	OEM Modules/Timeswitches
EL11	24hr Timeswitch – Panel Mounting
EL17	7 day Timeswitch – Panel Mounting

OEM Modules



EL11/EL17

Nightlights



EPNL5/EPNL5T



TGNL15/TGNL15T

Time & Heating Controllers



Trade Time Controllers



TS204/TS225/TS305



E169S



E269H



ELU1000/ELU7000



ELU56/ELU5620

Round Pattern Time Controllers



RTS113/RTS113Q
RTS114/RTS114Q



RTS173/RTS174/RTS274

SupplyMASTER



FST11/FST17

Cat No.

Cat No.	Trade Time Controllers
TS204	24hr 16A Electro-Mechanical Time Controller with Ind Mtr Connections
TS225	7 day 16A Electro-Mechanical Time Controller
TS305	24hr 16A Electro-Mechanical Time Controller
E169S	24hr 20A Electro-Mechanical Segment Dial Time Controller
E269H	24hr/7 day 20A Electro-Mechanical Time Controller
ELU1000	24hr 16A Electronic Time Controller
ELU7000	7 day 16A Electronic Time Controller
ELU56	7 day 16A Electronic Rail/Wall Mounting Time Controller
ELU5620	7 day 20A Electronic Time Controller
	Round Pattern Time Controllers
RTS113	24hr/Half Day & Day Omit 3 Pin 20A Round Pattern Timeswitch
RTS113Q	24hr/Half Day & Day Omit (Quartz Reserve) 3 Pin 20A Round Pattern Timeswitch
RTS114	24hr/Half Day & Day Omit Voltage Free 4 Pin 20A R/Pattern T/Switch
RTS114Q	24hr/Half Day & Day Omit Voltage Free (Quartz Reserve) 4 Pin 20A Round Pattern Timeswitch
RTS173	24hr/7 day 1 Channel 3 Pin 20A Round Pattern Timeswitch
RTS174	24hr/7 day 1 Channel Voltage Free 4 Pin 20A R/Pattern T/Switch
RTS274	24hr/7 day 2 Channel 4 Pin 2 x 10A Round Pattern Timeswitch
	SupplyMASTER Fused Spur Timeswitches
FST11	24hr Fused Spur Timeswitch
FST17	7 day Fused Spur Timeswitch
	Delhi Clocks
9DQ	Delhi 9" Quartz
12DQ	Delhi 12" Quartz
9DE	Delhi 9" Setric
12DE	Delhi 12" Setric
	Rightime Clocks
RT03N	Rightime 9" Quartz
RT05	Rightime 12" Quartz
RTR25	Rightime 9" Radio Controlled
RTR30	Rightime 12" Radio Controlled
	Timers
QB0130	Count Down/Count Up Electronic Timer

Clocks & Timers



Delhi



Rightime



Rightime
Radio Controlled



QB0130


theben



Theben TOP & Heating Controllers



TR608TOP

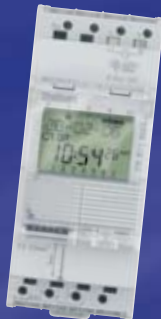

TR610TOP2
TR611TOP2
TR612TOP2



SEL170TOP



LU110



ELPA8



SYN160
SUL180



SYN161
SUL181



TR635TOP
TR636TOP

Time & Heating Controllers

Theben TERMINA TOP2 Digital Timeswitches

- 24hr/7 day, random and pulse programming.
- Push-in spring terminals (accepting 2 conductors, solid or strand) for a quicker installation.
- Simple 4 key text orientated programming.
- Obelisk memory card interface enables programming via a PC for on-site downloading.
- Single and 2 channel versions (2 module).
- Extended temperature range -30° to +55°C.



907-0-409

Cat No.

Cat No.	Theben Text-Oriented Programming (TOP)
TR608TOP	24hr/7 day 1 Channel (1 module) 16A Digital Timeswitch
TR610TOP2	24hr/7 day 1 Channel (2 Module) 16A Digital Timeswitch
TR611TOP2	24hr/7 day/Random day 1 Channel (2 Module) 16A Digital
TR612TOP2	24hr/7 2 Channel (2 Module) 16A Digital Timeswitch
SEL170TOP	Solar Timeswitch
TR635TOP	24hr/7 day/Random 16A Electronic Timeswitch
TR636TOP	24hr/7 day 2 Channel 6A Electronic Timeswitch
Theben Heating Controllers	
RAM701	Room Thermostat
RAM705	Room Thermostat with ON/OFF Switch
RAM721	24hr Clock Room Thermostat
RAM801TOP	Digital Clock Thermostat – 2 Programmes
RAM811TOP	Digital Clock Thermostat – 3 Programmes 2 x 1.5v AA battery powered
RAM812TOP	Digital Clock Thermostat – 3 Programmes
Theben Timeswitches	
ELPA8	Staircase Switch
SYN160	24hr Segment Timeswitch
SUL180	24hr Segment Timeswitch with Power Reserve
SYN161	24hr Segment Timeswitch (2 Module)
SUL181	24hr Segment Timeswitch with Power Reserve (2 Module)
LU110	Twilight Switch (2 Module)
907-0-409	Obelisk PC Programming Set

Theben Heating Controllers



RAM721



RAM701/RAM705



RAM801TOP/RAM811TOP/RAM812TOP