

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2183971052

Status:


Active

Overview:

Pico-SPOX Wire-to-Board Connector System

Description:

Pico-SPOX-to-Pigtail Off-the-Shelf (OTS) Cable Assembly, 1.50mm Pitch, Single Row, 150.00mm Length, Tin (Sn) Plating, 5 Circuits, Natural

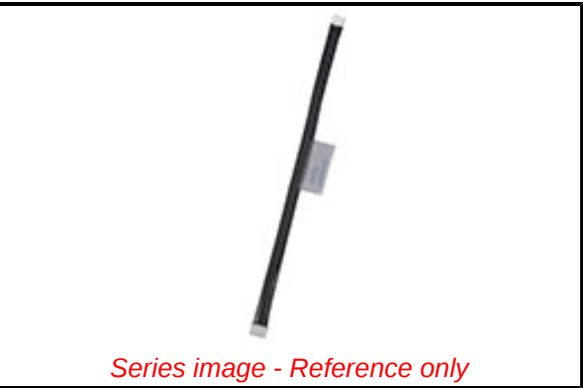

Documents:

[Drawing \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

[Datasheet \(PDF\)](#)

General	
Product Family	Cable Assemblies
Series	218397
Application	Signal, Wire-to-Board, Wire-to-Wire
Assembly Configuration	Single Ended Connector
Connector to Connector	N/A
Overview	Pico-SPOX Wire-to-Board Connector System
Product Name	Pico-SPOX
Type	Discrete Wire Assembly
UPC	195842352421
Physical	
Cable Length	150.00mm
Circuits (Loaded)	5
Color - Resin	Natural
Gender	Female-Pigtail
Lock to Mating Part	Yes
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Resin	Nylon
Net Weight	2.040/g
Number of Rows	1
Packaging Type	Bag
Pitch - Mating Interface	1.50mm
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Single Ended	Yes
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	0.95-1.20mm
Wire Size AWG	24
Wire/Cable Type	UL 10002
Electrical	
Current - Maximum per Contact	2.5A
Voltage - Maximum	250V
Material Info	
Reference - Drawing Numbers	
Sales Drawing	2183971050-000

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained Per - D(2021)4569-DC (8 July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

218397 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION