

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2183971054

Status:


Active

Overview:

Pico-SPOX Wire-to-Board Connector System

Description:

Pico-SPOX-to-Pigtail Off-the-Shelf (OTS) Cable Assembly, 1.50mm Pitch, Single Row, 600.00mm Length, Tin (Sn) Plating, 5 Circuits, Natural

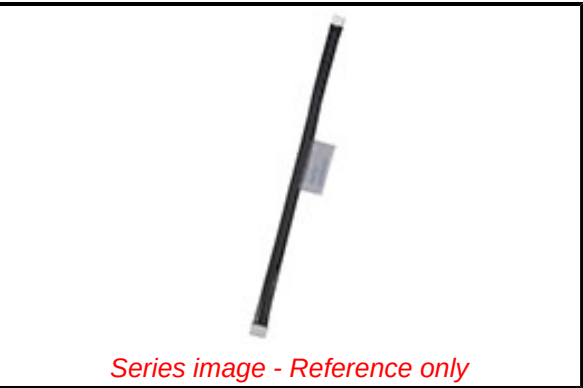

Series image - Reference only

Documents:

[Drawing \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

[Datasheet \(PDF\)](#)

General	
Product Family	Cable Assemblies
Series	218397
Application	Signal, Wire-to-Board, Wire-to-Wire
Assembly Configuration	Single Ended Connector
Connector to Connector	N/A
Overview	Pico-SPOX Wire-to-Board Connector System
Product Name	Pico-SPOX
Type	Discrete Wire Assembly
UPC	195842352445
Physical	
Cable Length	600.00mm
Circuits (Loaded)	5
Color - Resin	Natural
Gender	Female-Pigtail
Lock to Mating Part	Yes
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Resin	Nylon
Net Weight	7.190/g
Number of Rows	1
Packaging Type	Bag
Pitch - Mating Interface	1.50mm
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Single Ended	Yes
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	0.95-1.20mm
Wire Size AWG	24
Wire/Cable Type	UL 10002
Electrical	
Current - Maximum per Contact	2.5A
Voltage - Maximum	250V
Material Info	
Reference - Drawing Numbers	
Sales Drawing	2183971050-000

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2021)4569-DC (8 July 2021)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

218397 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION