



**order part 09238RA-12N-ET-00 Ball Bearing
Fan DC Axial Fans**

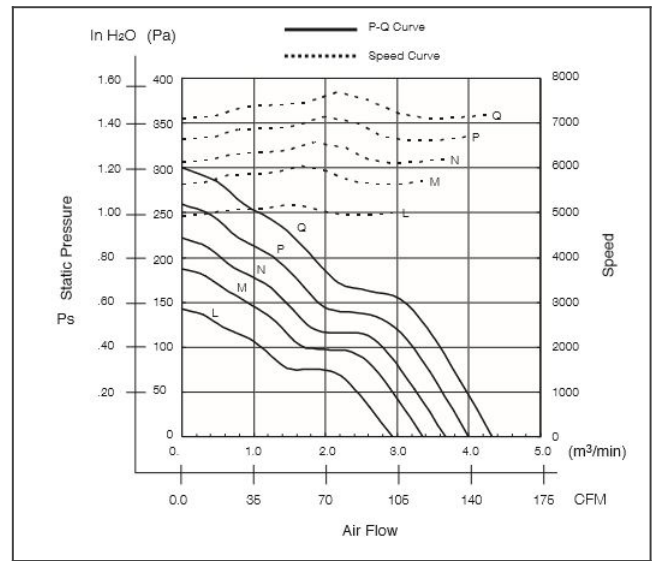


09238RA characteristic curve



09238RA product drawing

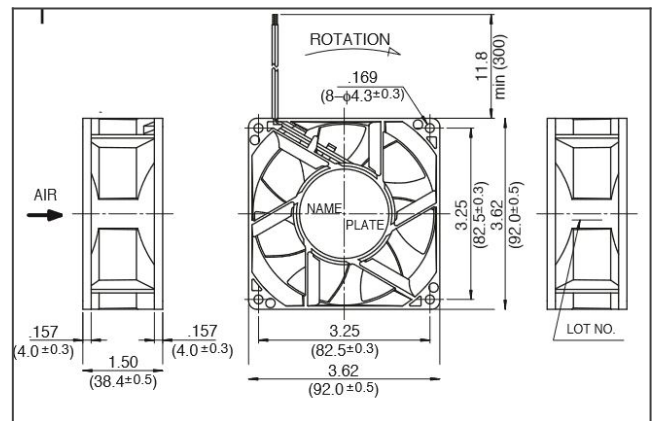

09238RA panel cut out

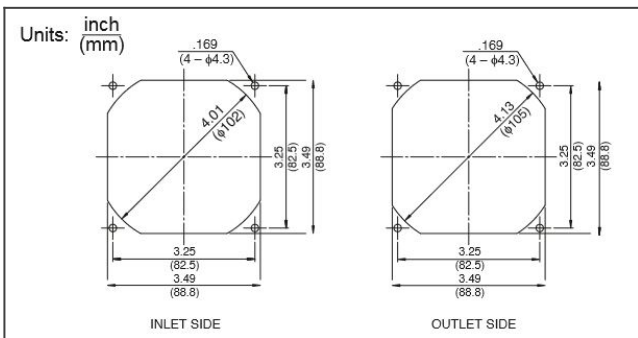

Detailed Specifications

Fan Size:	92[mm]
Fan Width:	38[mm]
Max. Air Flow:	129.9[CFM]
Max. Air Flow:	3.68[m3/min]
Max. Static Pressure:	0.89[In H2O]
Fan Speed:	6200[RPM]
Noise:	59[dB]
Life Expectancy:	25 degree C 100,000 Hours[L10]
Bearing Type:	Ball Bearing
Speed Control:	-
Nominal Voltage:	12[V]
Operating Voltage Lower:	7[V]
Operating Voltage Upper:	13.8[V]
Current:	1.46[A]
Input Power:	17.5[W]
Mass:	230[g]
IP Rating:	Standard