


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1731120052](#)
Status: **Active**
Overview: [FCT D-Sub Connectors](#)
Description: FCT Coaxial Contact, Male, Straight, Crimp, 50 Ohms, 1.30µm Gold Plating, for RG-316U Double Braided Cable

Documents:
[Brochure \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	D-Sub Products
Series	173112
Contact Type	Coaxial
Overview	FCT D-Sub Connectors
Product Category	Contacts
Product Name	FCT Products
Type	Mixed Layout
UPC	889056322935
Wire/Cable Type	RG-316U Double Braided
Physical	
Durability (mating cycles max)	500
Gender	Male
Material - Contact	Copper Alloy
Net Weight	1.300/g
Orientation	Straight
Packaging Type	Bag
Plating - Contact	Gold over Nickel
Plating min - Mating	0.800µm
Plating min - Termination	1.300µm
Temperature Range - Operating	-55° to +135°C
Termination Style	Crimp
Electrical	
Current - Maximum per Contact	2.0A
Impedance	50Ω
Material Info	
Engineering Number	FMS006P102

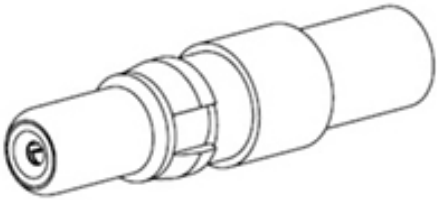

Series image - Reference only

EU ELV Not Relevant	
EU RoHS Compliant with Exemption 6(c) REACH SVHC Contained Per - ED/71/2019 (16 July 2019) lead Halogen-Free Status Not Reviewed For more information, please visit Contact US	China RoHS
China ROHS ELV RoHS Phthalates	50 Image Not Relevant Not Contained

Search Parts in this Series
[173112](#) Series

Use With
FCT Mixed Layout Connectors

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION