


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **2130287000**
Status: **Active**
Overview: CLIK-Mate Wire-to-Board Connectors
Description: CLIK-Mate 1.50mm Pitch Wire-to-Board Male Crimp Terminal, 0.76µm Gold Plating, 24-26 AWG, Reel

Documents:

| | |
|---|--|
| Drawing (PDF) | Product Specification 5031491002-PS-000 (PDF) |
| Product Specification 5025780004-PS-000 (PDF) | Packaging Specification 2130289200-SPK-200 (PDF) |
| Product Specification 5025781004-PS-000 (PDF) | RoHS Certificate of Compliance (PDF) |
| Product Specification 5031490002-PS-000 (PDF) | |

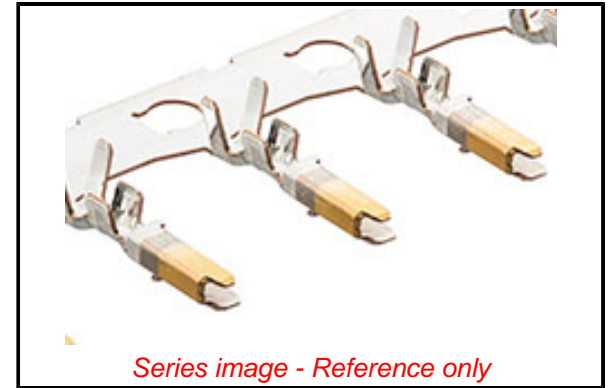

General

| | |
|-------------------------|---|
| Product Family | Crimp Terminals |
| Series | <u>213028</u> |
| Application | Signal, Wire-to-Board |
| Crimp Quality Equipment | Yes |
| Overview | <u>CLIK-Mate Wire-to-Board Connectors</u> |
| Product Name | CLIK-Mate |
| UPC | 193264238606 |

Physical

| | |
|--------------------------------|----------------------|
| Durability (mating cycles max) | 30 |
| Gender | Male |
| Material - Metal | Copper Alloy |
| Material - Plating Mating | Gold |
| Material - Plating Termination | Gold |
| Net Weight | 22.967/mg |
| Packaging Type | Reel |
| Plating min - Mating | 0.762µm |
| Termination Interface: Style | Crimp or Compression |
| Wire Insulation Diameter | 1.00-1.28mm |
| Wire Size AWG | 24, 26 |
| Wire Size mm ² | N/A |

Electrical

| | |
|-------------------------------|------------------|
| Current - Maximum per Contact | 2.0A |
| Voltage - Maximum | 100V AC (RMS)/DC |

Material Info

Reference - Drawing Numbers

| | |
|-------------------------|--|
| Packaging Specification | 2130289200-SPK-200 |
| Product Specification | 5025780004-PS-000, 5025781004-PS-000, 5031490002-PS-000, 5031491002-PS-000 |
| Sales Drawing | 2130280000-SD-000 |

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

213028 Series

Use With

CLIK-Mate Housing 503149

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description

Product #

Hand Crimp Tool for 2002187400
1.50mm Pitch CLIK-Mate Wire-to-Board Crimp Terminals, 24-28 AWG

Extractor Tool for 638133700
1.50mm Pitch Wire-to-Board Crimp Terminal

FineAdjust Applicator 639025000
for 1.50mm Pitch

Wire-to-Board Crimp
Terminals

Japan

Description

Product #

S-1 Applicator for
CLIK-Mate Plug
Terminals, 24-28
AWG

5780473700

This document was generated on 09/02/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION