

IDXPert™ MRO / Facility / Safety Labels

► INDOOR / OUTDOOR GRADE
FACILITY AND SAFETY LABELS

This indoor/5-yr outdoor vinyl is very pliable and conforms well to smooth or rough surfaces such as pipes, walls, door, panels, shelving, bins and equipment. Aggressive permanent adhesive. Excellent resistance to oils, detergents, dirt, grime and many solvents.

- **B-580 Indoor/Outdoor Vinyl** material, permanent adhesive, good for rough surfaces.
Temp Range: -40°F to 248°F (-40°C to 120°C).

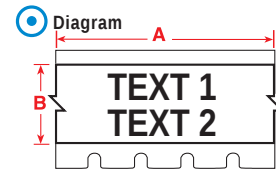


Diagram	Part Number	Labels per Cartridge	Dimensions – inches		Dimensions – mm		Color
			A	B	A	B	
⊙	XC-500-580-WT-BK	1 roll (cont.)	30 ft.	0.500	9.14 m	12.70	BK on WT
⊙	XC-1000-580-WT-BK	1 roll (cont.)	30 ft.	1.000	9.14 m	25.40	BK on WT
⊙	XC-1500-580-WT-BK	1 roll (cont.)	30 ft.	1.500	9.14 m	38.10	BK on WT
⊙	XC-500-580-OR-BK	1 roll (cont.)	30 ft.	0.500	9.14 m	12.70	BK on OR
⊙	XC-1000-580-OR-BK	1 roll (cont.)	30 ft.	1.000	9.14 m	25.40	BK on OR
⊙	XC-1500-580-OR-BK	1 roll (cont.)	30 ft.	1.500	9.14 m	38.10	BK on OR
⊙	XC-500-580-YL-BK	1 roll (cont.)	30 ft.	0.500	9.14 m	12.70	BK on YL
⊙	XC-1000-580-YL-BK	1 roll (cont.)	30 ft.	1.000	9.14 m	25.40	BK on YL
⊙	XC-1500-580-YL-BK	1 roll (cont.)	30 ft.	1.500	9.14 m	38.10	BK on YL
⊙	XC-500-580-CL-BK	1 roll (cont.)	30 ft.	0.500	9.14 m	12.70	BK on CL
⊙	XC-1000-580-CL-BK	1 roll (cont.)	30 ft.	1.000	9.14 m	25.40	BK on CL
⊙	XC-1500-580-CL-BK	1 roll (cont.)	30 ft.	1.500	9.14 m	38.10	BK on CL
⊙	XC-500-580-RD-WT	1 roll (cont.)	30 ft.	0.500	9.14 m	12.70	WT on RD
⊙	XC-1000-580-RD-WT	1 roll (cont.)	30 ft.	1.000	9.14 m	25.40	WT on RD
⊙	XC-1500-580-RD-WT	1 roll (cont.)	30 ft.	1.500	9.14 m	38.10	WT on RD
⊙	XC-500-580-GN-WT	1 roll (cont.)	30 ft.	0.500	9.14 m	12.70	WT on GN
⊙	XC-1000-580-GN-WT	1 roll (cont.)	30 ft.	1.000	9.14 m	25.40	WT on GN
⊙	XC-1500-580-GN-WT	1 roll (cont.)	30 ft.	1.500	9.14 m	38.10	WT on GN
⊙	XC-500-580-BL-WT	1 roll (cont.)	30 ft.	0.500	9.14 m	12.70	WT on BL
⊙	XC-1000-580-BL-WT	1 roll (cont.)	30 ft.	1.000	9.14 m	25.40	WT on BL
⊙	XC-1500-580-BL-WT	1 roll (cont.)	30 ft.	1.500	9.14 m	38.10	WT on BL
⊙	XC-500-580-WT-RD	1 roll (cont.)	30 ft.	0.500	9.14 m	12.70	RD on WT
⊙	XC-1000-580-WT-RD	1 roll (cont.)	30 ft.	1.000	9.14 m	25.40	RD on WT
⊙	XC-1500-580-WT-RD	1 roll (cont.)	30 ft.	1.500	9.14 m	38.10	RD on WT

