

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0795762107](#)
Status: **Active**
Overview: [iPass Connector System](#)
Description: Internal iPass Mini SAS Double-Ended Plug with Sidebands, 36 Circuits, 30 AWG, 0.23m Length, Controller-to-Backplane, Pinout 1

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable Assemblies
Series	79576
Assembly Configuration	Dual Ended Connectors
Connector to Connector	iPass-to-iPass
Overview	iPass Connector System
Product Name	iPass, Mini Multi-Lane, PCI Express, SAS
UPC	800756696539

Physical

Cable Length	0.23m
Circuits (Loaded)	36
Color - Resin	Black, Natural
Gender	Plug
Lock to Mating Part	Yes
Material - Resin	Low Density Polyethylene, Polyester
Net Weight	25.000/g
Packaging Type	Bag
Single Ended	No
Termination Interface: Style	Crimp or Compression
Waterproof / Dustproof	No
Wire Insulation Diameter	N/A
Wire Size AWG	30
Wire/Cable Type	Twinax


Electrical

Shielded No

Material Info

Reference - Drawing Numbers

Sales Drawing SD-79576-200-001

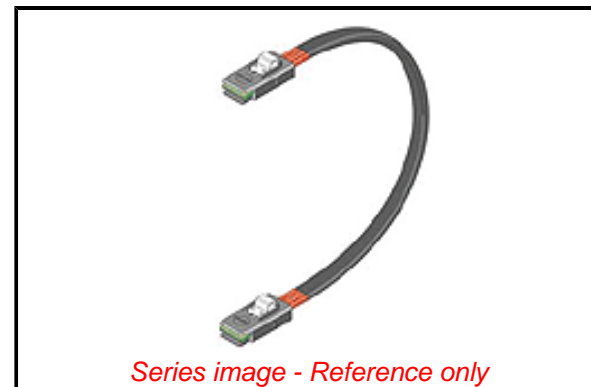

Series image - Reference only

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Compliant

Not Contained

Search Parts in this Series

[79576](#) Series

Mates With

[75783](#) iPass Right Angle Connector. [75784](#) iPass Vertical Connector