

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0638117600](#)  
**Status:** **Active**  
**Overview:** [Application Tooling](#)  
**Description:** Hand Crimp Tool

**Documents:**

[RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Application Tooling
Series	<a href="#">207129</a>
Comments	Type: 4A
Function	Crimp
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	<a href="mailto:applicationtooling@molex.com">applicationtooling@molex.com</a>
Overview	<a href="#">Application Tooling</a>
Product Name	N/A
Tool Type	Hand Crimp Tool
UPC	822350766852
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.


**Physical**

Net Weight 428.885/zg

**Material Info**

**Reference - Drawing Numbers**

Application Tooling Documents  
ATS-6381176HM-001, TM-638000029-001, TM-638000029CN-001, TM-638000029DE-001, TM-638000029FR-001, TM-638000029IT-001, TM-638000029JP-001, TM-638000029KR-001, TM-638000029MY-001, TM-638000029PL-001, TM-638000029RU-001, TM-638000029SK-001, TM-638000029SP-001, TM-638000029TH-001, TM-638000029TW-001, TM-638000029VN-001

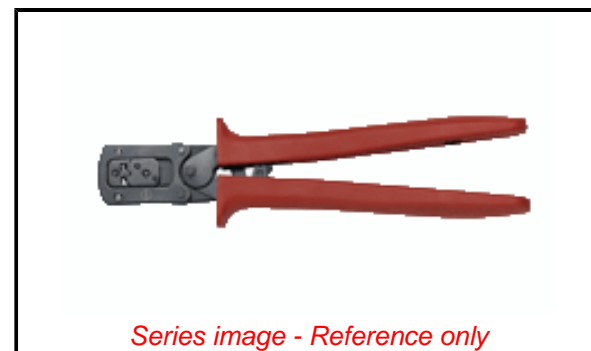

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per - ED/61/2018 (27 June 2018)

**Halogen-Free**

**Status**

**Not Relevant**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Not Relevant

Not Relevant

Not Contained

**Search Parts in this Series**

[207129](#) Series

**Use With**

Loose Piece Terminals

**Application Tooling**

**Description**

**FAQ**

**Product #**

MX150L Male [194170024](#)

Terminal for 18-22 AWG Wire, Metal Strip Carrier, Length 25.40mm

MX150L Male [194170026](#)

Terminal for 18-22 AWG Wire, Metal Strip Carrier, Length 25.40mm , Gold Plated

MX150L Male [194170028](#)

Terminal for 18-22 AWG Wire, Metal Strip Carrier, Length 26.16mm

MX150L Male [194170030](#)

Terminal for 18-22

AWG Wire, Length  
26.16mm , Metal  
Strip Carrier, Gold  
Plated

MX150L Male 194170048

Terminal for 18-22  
AWG Wire, Length  
25.40mm

MX150L Female 194200002

Terminal for 18-22

AWG Wire, Tin  
Plated, Metal Strip  
Carrier

MX150L Female 194200004

Terminal for 18-22

AWG Wire, Gold  
Plated, Metal Strip  
Carrier

MX150L Female 194200010

Terminal for 18-22

AWG Wire, Tin  
Plated

This document was generated on 11/02/2021

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**