

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0638119100](#)
Status: **Active**
Overview: [Application Tooling](#)
Description: PremiumGrade Hand Crimp Tool for CP 0.635mm Female Terminals for CMC Connector, 0.22-0.35mm² Wire


Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

General
Product Family Application Tooling
Series [207129](#)
Comments Field Repair, See Tooling Specification (PDF) Above.
Type: 7
Function Crimp
Geographic Area Global
Level of Automation Manual
More Detailed Tech Information [applicationtooling@molex.com](#)
Overview [Application Tooling](#)
Product Name PremiumGrade
Tool Type Hand Crimp Tool
UPC 822350980487
Warranty Disclaimer CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Physical
Net Weight 0.001/kg

Material Info

Reference - Drawing Numbers
Application Tooling Documents
ATS-638119100-001, TM-638000029-001, TM-638000029CN-001, TM-638000029DE-001, TM-638000029FR-001, TM-638000029IT-001, TM-638000029JP-001, TM-638000029KR-001, TM-638000029MY-001, TM-638000029PL-001, TM-638000029RU-001, TM-638000029SK-001, TM-638000029SP-001, TM-638000029TH-001, TM-638000029TW-001, TM-638000029VN-001

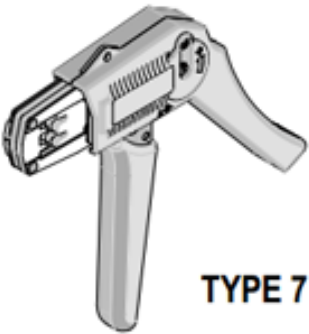

TYPE 7

Series image - Reference only

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per - ED/30/2017 (7 July 2017)
Halogen-Free
Status
Not Relevant
For more information, please visit [Contact US](#)

China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[207129 Series](#)

Use With
Loose Piece Terminals

Application Tooling Description	FAQ Product #
0.635mm CMC CP Female Terminal, Tin Plated, for Square 0.6mm x 0.6mm Pins, Wire Size 0.35mm ²	643221019
0.635mm CMC CP Female Terminal, Tin Plated, Selective 1.27µm Gold in Contact Area, for Square 0.6mm x 0.6mm Pins, Wire Size 0.35mm ²	643221229
0.635mm CMC CP Female Terminal, HP VERSION, Tin	643221349

Plated, Selective
1.27μm Gold in
Contact Area, for
Square 0.6mm x
0.6mm Pins, Wire
Size 0.35mm²

This document was generated on 11/02/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION