

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0638270900](#)
Status: **Active**
Overview: [Application Tooling](#)
Description: PremiumGrade Hand Crimp Tool for Pico-Lock Female Terminals, 30-32 AWG

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)


General

| | |
|--------------------------------|---|
| Product Family | Application Tooling |
| Series | 207129 |
| Comments | See Tooling Specification (PDF) Above. Type: 4A |
| Function | Crimp |
| Geographic Area | Global |
| Level of Automation | Manual |
| More Detailed Tech Information | applicationtooling@molex.com |
| Overview | Application Tooling |
| Product Name | PremiumGrade |
| Tool Type | Hand Crimp Tool |
| UPC | 887191391441 |
| Warranty Disclaimer | CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified. |

Material Info

Reference - Drawing Numbers
[Application Tooling Documents](#)

ATS-638270900-001, TM-638000029-001

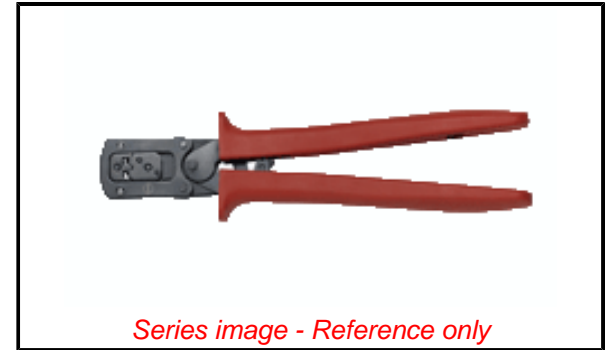

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[207129](#) Series

Use With

[504052](#) 1.50mm (.059") Pitch Wire-to-Board Crimp terminal, 30-32 AWG

Application Tooling Description

FAQ Product #

1.50mm Pitch, Pico-Lock Female Crimp Terminal, Gold (Au) Plating, 30-32 AWG, Reel [5040520298](#)