


**wiring information**

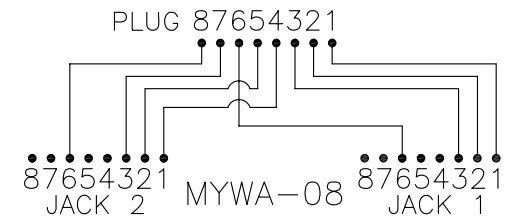


**Specification**

1. Upper & Button Case : ABS UL94 HB, white color.
2. RJ45 plug : PC UL94 V0, contact is 6u" gold plating.
3. RJ45 Jack : Body: PBT UL94 V0 rated.  
Contact: Phosphor Bronze with 50u" gold plated over nickel plated in contact area.  
Tin-lead over nickel in solder area.
4. Cable: Cat.5e cable ,4pair ,24AWG
5. P.C.B : 1.6m/m , double side , FR4.
6. Operation Temperature : -40°C to 80°C.
7. Insertion Force : 900gms for 8 contacts.
8. Retention Strength : 7.7 kgs between jack and plug.
9. Durability :  
750 Cycles contact resistance test check every 100 cycles. Insertion cycles at 20 cycles/minute max.

Note: Jack1.Red Jack2.Blue

**RoHS Compliant**

	DSGN	CSQ	24.MAY.2007	ITEM NO: <b>4264</b>
	CHK	Maer	24.MAY.2007	
UNIT M/M	APPR	Yty	24.MAY.2007	Unshielded "Y" Adaptor
SCALE 1/1	<p style="text-align: center;"><b>Videk Ltd</b></p>			
DWG NO: 4264				