

## Network RJ45 Patch Cables Cat6a Patch Cables

Part No: 2996AS - (Length) + (Colour) see chart

These S/FTP Cat6a cables are designed to support high-bandwidth and high-speed applications, manufactured using premium cable and with two shielding layers to ensure that crosstalk is kept at the lowest possible levels.

### Features & Benefits

- Designed to support high-bandwidth & high-speed applications
- Premium Cable, Stranded core 26AWG, Double Shielded, LSZH Jacket
- Wide choice of 10 colours – helping to identify cable paths at a glance
- Manufactured using quality component parts: 50 micron gold RJ45 plugs


### Specification

#### Material: RJ45

- Housing : Polycarbonate, UL 94V-2, Transparent color
- Contact material : Phosphor Bronze with 50-60 micro-inch Nickel plated
- Contact finished : Min. 50 micro-inch with Gold plated on surface contact area
- Shield : Bronze with Nickel plated

#### Cable:

- Jacket : LSOH
- Conductor : 26 AWG stranded copper
- Isolation : PE
- Shield : Aluminium Foil Shielded for Each Pair, Tin Copper Braid

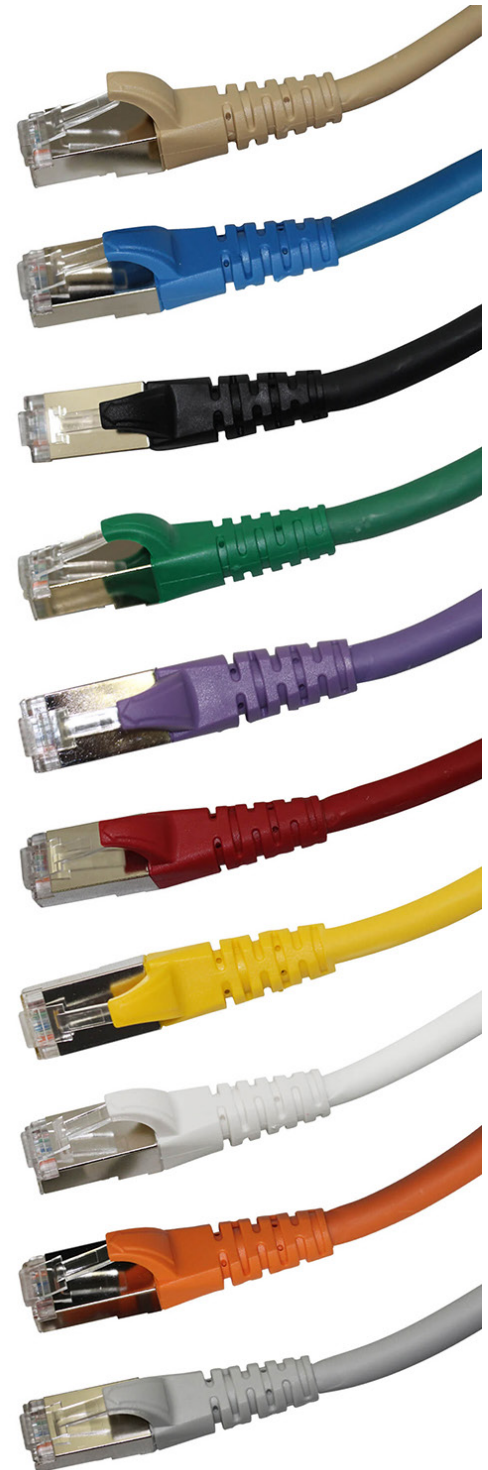




# VIDEK

## Shielded Cat6A S/FTP Patch Cables

Part No: 2996AS - (Length) + (Colour) see chart

### Part Number Chart






Length	Beige 	Blue 	Black 	Green 	Grey 
0.3 Metre	2996AS-0.3	2996AS-0.3B	2996AS-0.3BK	2996AS-0.3G	2996AS-0.3GY
0.5 Metre	2996AS-0.5	2996AS-0.5B	2996AS-0.5BK	2996AS-0.5G	2996AS-0.5GY
1 Metre	2996AS-1	2996AS-1B	2996AS-1BK	2996AS-1G	2996AS-1GY
1.5 Metre	2996AS-1.5	2996AS-1.5B	2996AS-1.5BK	2996AS-1.5G	2996AS-1.5GY
2 Metre	2996AS-2	2996AS-2B	2996AS-2BK	2996AS-2G	2996AS-2GY
3 Metre	2996AS-3	2996AS-3B	2996AS-3BK	2996AS-3G	2996AS-3GY
4 Metre	2996AS-4	2996AS-4B	2996AS-4BK	2996AS-4G	2996AS-4GY
5 Metre	2996AS-5	2996AS-5B	2996AS-5BK	2996AS-5G	2996AS-5GY
8 Metre	2996AS-8	2996AS-8B	2996AS-8BK	2996AS-8G	2996AS-8GY
10 Metre	2996AS-10	2996AS-10B	2996AS-10BK	2996AS-10G	2996AS-10GY
15 Metre	2996AS-15	2996AS-15B	2996AS-15BK	2996AS-15G	2996AS-15GY
20 Metre	2996AS-20	2996AS-20B	2996AS-20BK	2996AS-20G	2996AS-20GY

# VIDEK

## Shielded Cat6A S/FTP Patch Cables

Part No: 2996AS - (Length) + (Colour) see chart

### Part Number Chart

Length	Orange 	Purple 	Red 	White 	Yellow 
0.3 Metre	2996AS-0.3RG	2996AS-0.3PR	2996AS-0.3R	2996AS-0.3W	2996AS-0.3Y
0.5 Metre	2996AS-0.5RG	2996AS-0.5PR	2996AS-0.5R	2996AS-0.5W	2996AS-0.5Y
1 Metre	2996AS-1RG	2996AS-1PR	2996AS-1R	2996AS-1W	2996AS-1Y
1.5 Metre	2996AS-1.5RG	2996AS-1.5PR	2996AS-1.5R	2996AS-1.5W	2996AS-1.5Y
2 Metre	2996AS-2RG	2996AS-2PR	2996AS-2R	2996AS-2W	2996AS-2Y
3 Metre	2996AS-3RG	2996AS-3PR	2996AS-3R	2996AS-3W	2996AS-3Y
4 Metre	2996AS-4RG	2996AS-4PR	2996AS-4R	2996AS-4W	2996AS-4Y
5 Metre	2996AS-5RG	2996AS-5PR	2996AS-5R	2996AS-5W	2996AS-5Y
8 Metre	2996AS-8RG	2996AS-8PR	2996AS-8R	2996AS-8W	2996AS-8Y
10 Metre	2996AS-10RG	2996AS-10PR	2996AS-10R	2996AS-10W	2996AS-10Y
15 Metre	2996AS-15RG	2996AS-15PR	2996AS-15R	2996AS-15W	2996AS-15Y
20 Metre	2996AS-20RG	2996AS-20PR	2996AS-20R	2996AS-20W	2996AS-20Y