



## R.5 | R 1/4" drive metric 6-point sockets



### Description:

- OGV® profile: more powerful tightening, preserves fasteners.
- Finish: bright chrome.
- Available as sets on metal rack (Ref R.40E).

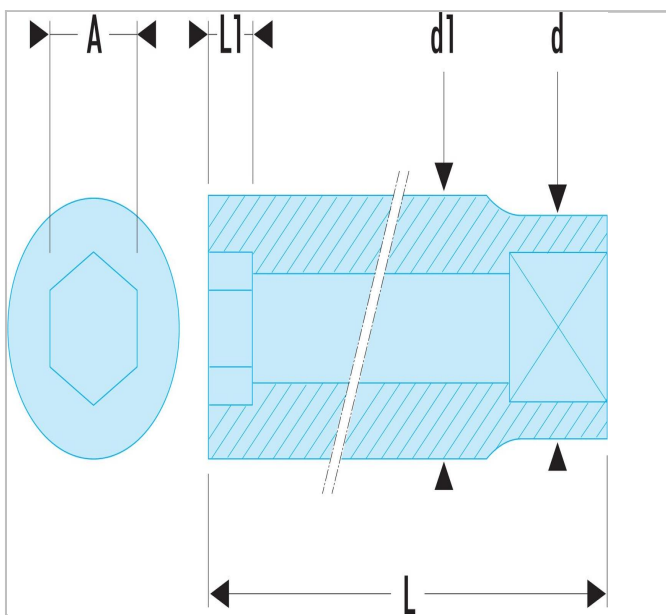

	R.5
A [mm]	5.0
Diameter [mm]	11.2
Diameter D1 [mm]	8.2
Length L [mm]	22.0
Length L1 [mm]	4.8
Height H3 [mm]	4.8