


OMEGAFLEX® POLYPROPYLENE TUBING

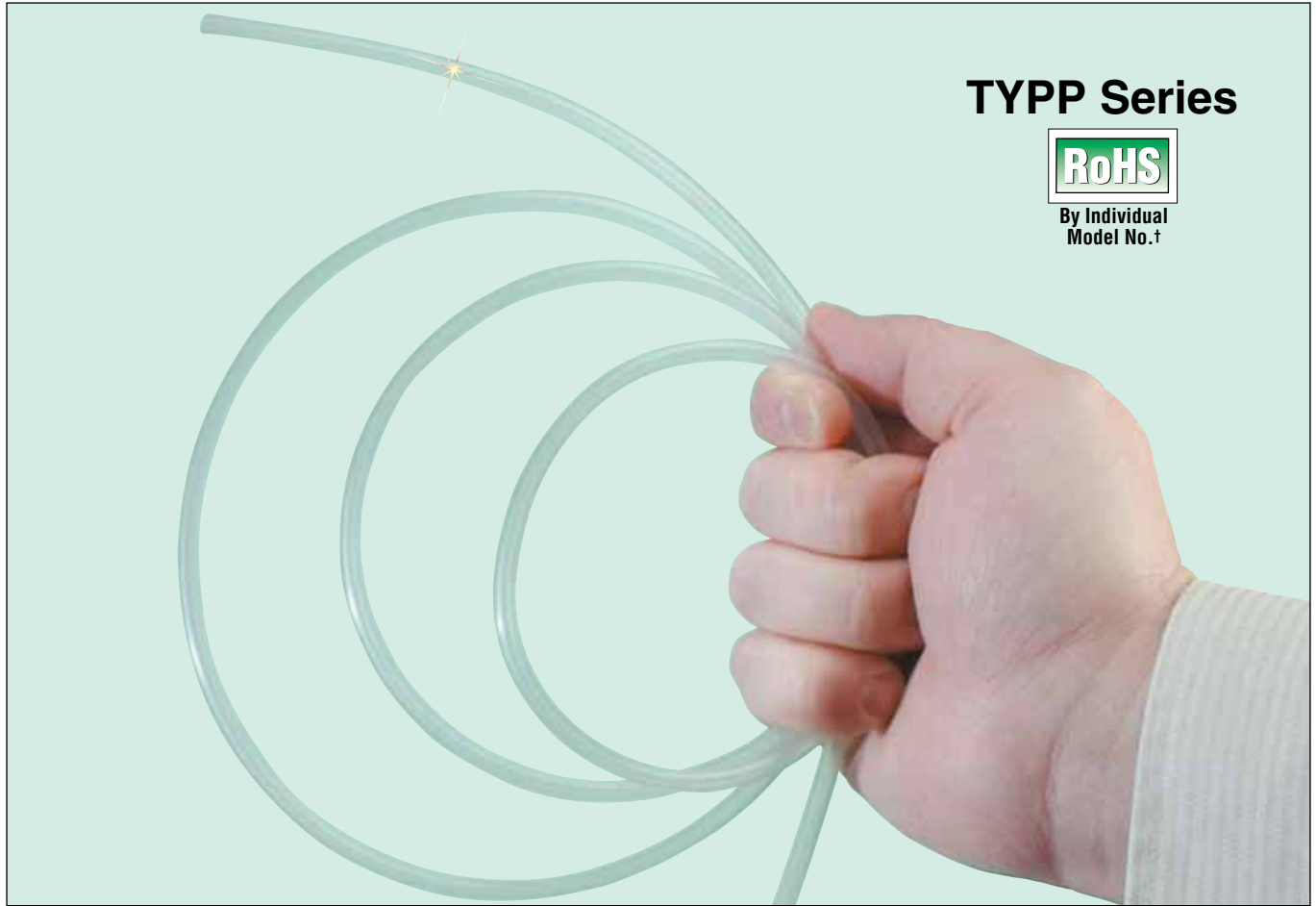

TYPP Series



By Individual
Model No.†

This is a tough, heat-resistant tubing, ideal for the transfer of hot liquids or gases. It is recommended for low pressure systems and applications where higher temperatures and pressures are encountered. It has good compatibility to acids and alkalies.

SPECIFICATIONS*

Service Temperature:

-40 to 121°C (-40 to 250°F)

Durometer, nom. (Shore) 15 secs: 75 (D)

Color: Translucent

Specific Gravity: 0.90

Tensile Strength (PSIG): 3700

Ultimate Elongation: 200%

Minimum Bend Radius:
ten times tube OD

**Specifications given are typical and are meant only as a guide. Field testing is required to find the actual operating specifications in a given application.*

† Visit omega.com/rohs to determine specific RoHS compliance.

To Order

Model No.	Standard Length	Wall	OD	ID	Working psi @ 70°F	Weight (lbs)
TYPP-1418-100	100'	1/16"	1/4"	1/8"	272	3.0
TYPP-14170-100	100'	0.04"	1/4"	0.17"	149	1.5
TYPP-516316-100	100'	1/16"	5/16"	3/16"	196	3.0
TYPP-3814-100	100'	1/16"	3/8"	1/4"	157	3.1
TYPP-1238-100	100'	1/16"	1/2"	3/8"	112	5.0
TYPP-5812-100	100'	1/16"	5/8"	1/2"	87	6.0
TYPP-3458-100	100'	1/16"	3/4"	5/8"	71	7.0
TYPP-134-100	100'	1/8"	1"	3/4"	109	13.1
TYPP-1141-100	100'	1/8"	1 1/4"	1"	87	13.5
TYPP-112114-100	100'	1/8"	1 1/2"	1 1/4"	71	21.3
TYPP-2134-100	100'	1/8"	2"	1 3/4"	52	29.1

Ordering Examples: TYPP-1418-100, 100' of tubing, 1/4" OD x 1/8" ID.

TYPP-14170-100, 100' of tubing, 1/4" OD x 0.17" ID.