

# Display Adapters & Convertors

## DisplayPort Adapters

Part No: 2409ED

This high quality adaptor supports the link from a PC featuring the DisplayPort interface to a DVI display.

### Specification

● <b>Input</b>	<b>Output</b>
DisplayPort M	VGA F
Max 1920x1200	Max 1920x1200
● <b>Operating Frequency</b>	
Vertical Frequency Range	50/60Hz
	162Mhz
Bandwidth	225MHz/2.25 Gbps / channel
● <b>Physical</b>	
Size (LxWxD)	45 x 45 x 15mm
Weight (Net)	30g
Colour	Black
Connector	Nickel Plated
● <b>Operational</b>	
Operating Temperature	0 °C to +55 °C
Operating Humidity	10% to 85% RH (no condensation)
Storage Temperature	0 °C to +70 °C
Storage Humidity	5% to 90% RH (no condensation)
● <b>Power Requirement</b>	
	No external power needed
● <b>Regulatory Approvals</b>	
	CE, FCC, RoHS




### Features & Benefits

- V1.2 available with 4K2K support
- V1.2 Compatible for 3+ Monitors
- V1.1 with resolutions up to 1920x1200
- Support Video Bandwidth to 10.8Gbps
- Support Full DisplayPort Link 20 Pin
- With latch-lock

## Display Adapters & Convertors

### DisplayPort Adapters

Part No: 2409ED

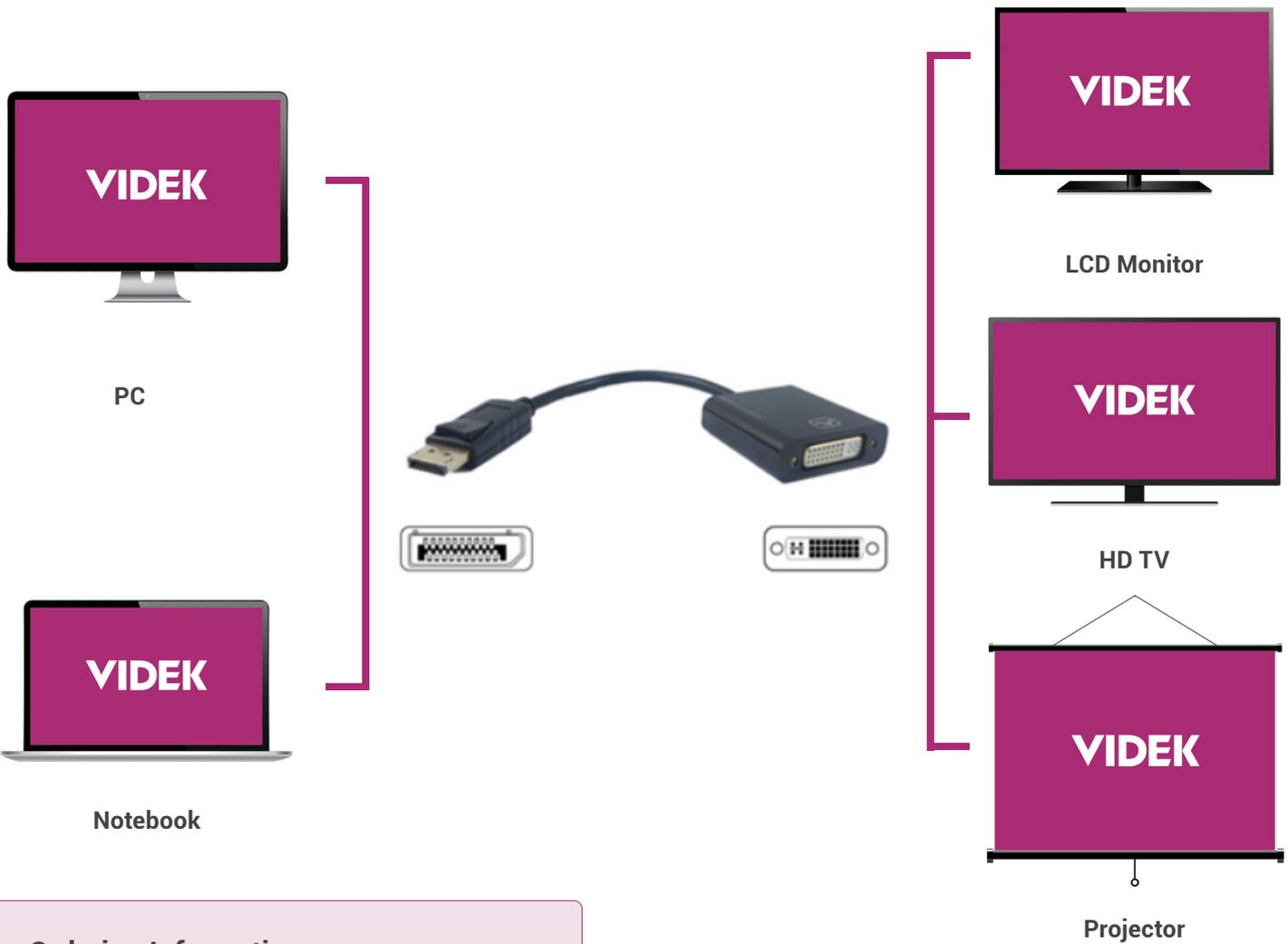

#### Ordering Information

- **Part No:**  
2409ED
- **Product Description:**  
VIDEK DisplayPort Plug to DVI Socket Adaptor - Black