
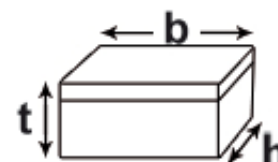


Polyester Standard – 02.25 26 12

Plastic enclosure in glass fibre reinforced polyester consisting of lid, seal, incl. captive +/-stainless steel screws, base with 2 or 4 earthing screws

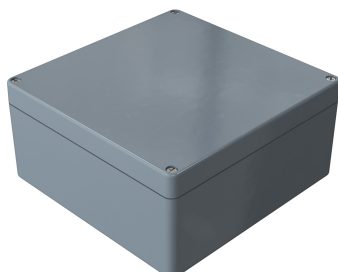

Dimensions H x W x D (mm)	250 x 255 x 121
Weight (g)	2886
Order number	02.25 26 12
Product type	POS 02105

- + Robust plastic enclosure for automation technology and mechanical engineering
- + Fixing options for DIN rails and mounting plates
- + Universal configuration




Technical Data

Material	glass fibre reinforced thermoset polyester
Colour	RAL 7000, squirrel grey, special colour on request
Ingress protection	IP 66 to EN 60529 (IP 67 on request)
Impact resistance	7 Joule in reference to EN 60079-0
Temperature range	CR (chloroprene) seal: -40°C to +100°C
Other versions on request	EMC, Silicone lid seal

Polyester Standard – 02.25 26 12

Number of cable glands

Maximum number of cable glands to DIN 50262*

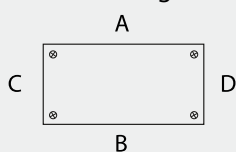

M	PG	Side A/B	C/D
12	17,25	69	51
16	25,30	32	24
20	27,60	24	18
25	37,95	12	10
32	48,30	8	7
40	60,95	4	3
50	69,00	3	3
63	74,75	3	2
75			
85			

Commercial Data

Country of origin	IN
Pieces per packaging	1
Customs tariff number	39269097
Weight (g)	2886
GTIN	4250157900692

ETIM Classification

ETIM-Class	EC000058
------------	----------

Accessories

Description	Order number
External hinges Swivelling range 150°set = 2 pcs	10.02 70 01
DIN rails TS 35/7,5	10.06 14 34
Earth rail	10.06 20 05
Mounting plate	10.01 11 15
External mounting brackets set = 4 pcs	10.03 11 02
Allen lid screws	12.01 80 08
sealable screw	12.01 90 02